


Frame Type Plug-In Unit PRO Kit, With Hood, Shielded Version, 3 U, 7 HP, 227 mm

Power Utilities

KATALOGNUMMER

24813-057

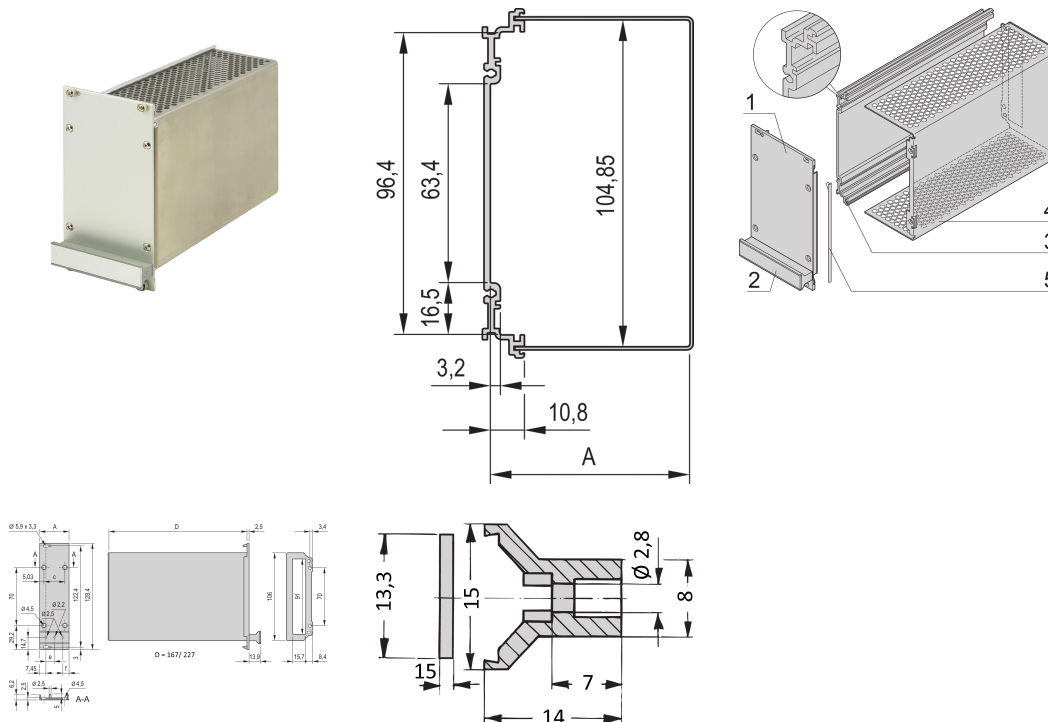

Protects a PCB against mechanical damage and discharges electrostatic buildup; for Euroboard formats.

CERTIFIERINGAR



DESIGN

Fits all products conforming to IEC-60297-3-101

Protects a PCB against mechanical damage and discharges electrostatic buildup; for Euroboard formats

Connectors usable under EN 60603-2 (DIN 41612)

PRODUKTATTRIBUT

Produkttyp: Kassett

Typ: Ramtyp Plug-in enheter PRO med huva

Handtagstyp: Trapets

Rackhöjd: 3 U

Rackbredd: 7 HP

Djup: 227 mm

EMC-skärmning: Ja

EMC-packningstyp: Textil

Typ av bakpanel: Frånkoppling av enkel kontakt

Typ av täckplatta: Motljusskydd

Material: Aluminium

Främre finish: Anodiserad

Bakre finish: Ledande

Kylning: Perforerad

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplikering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE