
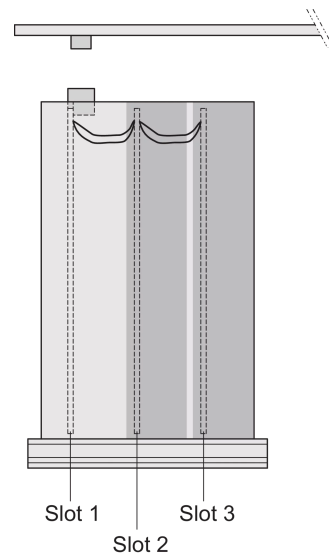
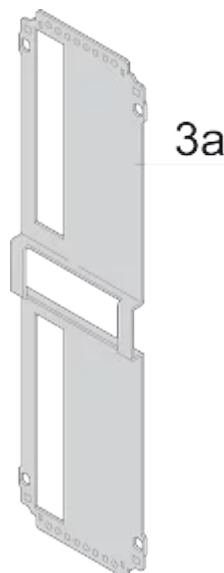
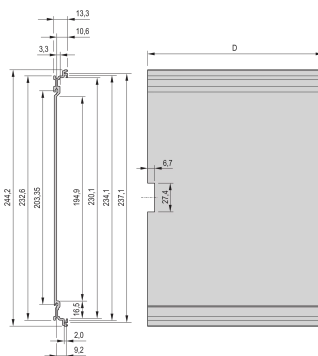
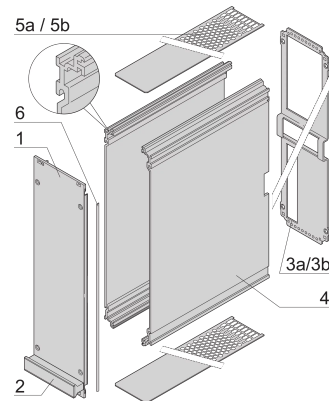


**Frame Type Plug-In Unit PRO Kit, Shielded,
Plain Cover, 1 Connector, 6 U, 10 HP, 227 mm**

Power Utilities

KATALOGNUMMER

24813-960

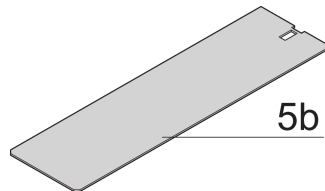

Protects a PCB against mechanical damage and discharges electrostatic buildup; for Euroboard formats; with plain covers; rear panel with one cutout for one connector.



DESIGN

Rear panel with cut-out for single connector (conforms to EN 60603, DIN 41612, construction types: B, C, D, F, H, Q, R, S)

Extruded side panels with groove to right and left, to insert a PCB (board position in accordance with standard in left side panel only)

Plain cover plates

PRODUKTATTRIBUT

Produkttyp: Kassett

Typ: Ramtyp Plug-in Units PRO

Handtagstyp: Trapets

Rackhöjd: 6 U

Rackbredd: 10 HP

Djup: 227 mm

EMC-skärmning: Ja

EMC-packningstyp: Textil

Typ av bakpanel: Frånkoppling av enkel kontakt

Typ av täckplatta: Täckplatta utan perforering

Material: Aluminium

Främre finish: Anodiserad

Bakre finish: Anodiserad

YTTERLIGARE PRODUKTINFORMATION

Guide rails, 2 rear panel retainers and PCB fixing for slot 1 and one slot 2 are already included. Where additional PCBs without rearward connectors are to be fitted, guide rail (part no. 24812-101) and 'PCB fixing from slot 2' (part no. 24812-301 + screw, part no. 24560-178) are also required.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE