


U-profile Front Panel, Shieldable, D-Sub Cutouts, 3 U, 4 HP, 1 x 9 Pin

Power Utilities

KATALOGNUMMER

30849-749

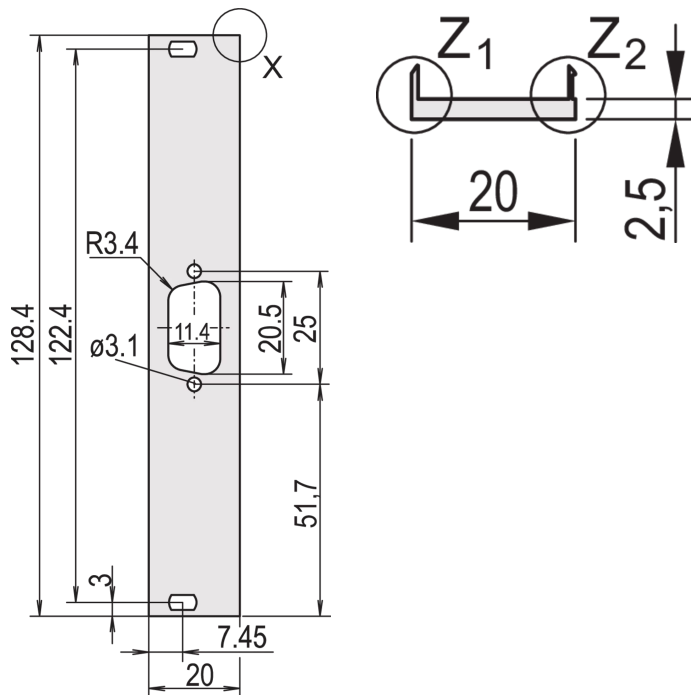

U-profile front panel with cutout for D-Sub connectors. Shieldable for textile EMC gasket.

CERTIFIERINGAR



DESIGN

U-profile, front panel, Aluminum, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

PRODUKTATTRIBUT

Produkttyp: Frontpanel

Typ: Frontpanel utan handtag

Montering: Skruvfront

EMC-skärmning: Nej (kan eftermonteras)

EMC-packningstyp: Textil

Material: Aluminium

Främre finish: Anodiserad

Bakre finish: Ledande

Behandlade kanter: Nej

Rackhöjd: 3 U

Höjd: 128.4 mm

Rackbredd: 4 HP

Bredd: 20 mm

Överensstämmer med.: IEC 60297-3-101; IEEE 1101.1/10

Förpackningskvantitet: 5

YTTERLIGARE PRODUKTINFORMATION

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE