


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, SNCF

Energiföretag

Subrack for Railway applications, conform to SNCF Standard, non-shielded versions.

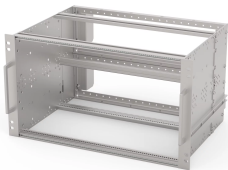

CERTIFIERING



FUNKTIONER

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

SPECIFIKATIONER

Table 1/3

Katalognummer	Rack Height	Rack Width	Djup	Package Quantity	For Mounting	Board Depth
21500-027	6 U	84 HP	320 mm	1	Backplane	220 mm
21500-029	3 U	84 HP	320 mm	1	Backplane	220 mm
21500-067	3 U	36 HP	320 mm	1	Backplane	220 mm
21500-070	6 U	36 HP	320 mm	1	Backplane	220 mm

Table 2/3

Katalognummer	EMC Gasket Type	Shock and Vibration Tolerance	Handle Included	Montering	Uppfyller kraven enligt	EMC Shielding
21500-027	Textile	5 g (force)	Ja	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Nej
21500-029	Textile	5 g (force)	Ja	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Nej
21500-067	Textile	5 g (force)	Ja	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Nej
21500-070	Textile	5 g (force)	Ja	Rack	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Nej

Table 3/3

Katalognummer	Product Type	Statisk belastning	Certifiering
21500-027	Subrack/Chassis	15 kgf	RoHS, SNCF
21500-029	Subrack/Chassis	15 kgf	RoHS, SNCF
21500-067	Subrack/Chassis	15 kgf	RoHS

Katalognummer	Product Type	Statisk belastning	Certifiering
21500-070	Subrack/Chassis	15 kgf	RoHS

ADDITIONAL PRODUCT DETAILS

Test reports are available online.

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE