


Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts

Energiföretag

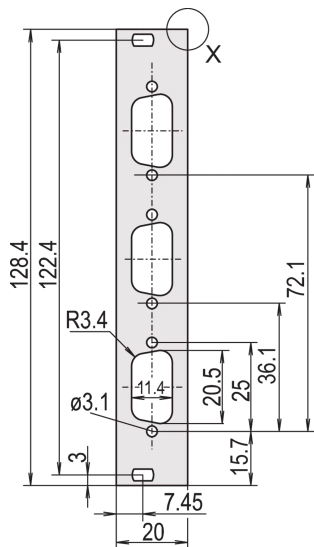

Flat front panel with cutout for D-Sub connectors.
Shieldable for stainless steel EMC gasket.

CERTIFIERING



FUNKTIONER

For stainless steel EMC gasket

Aluminum, 2.5 mm, front anodized, conductive

SPECIFIKATIONER

Table 1/3

Katalognummer	Package Quantity	Montering	EMC Gasket Type	Front Finish	Rear Finish	Treated Edges
---------------	------------------	-----------	-----------------	--------------	-------------	---------------

30118-348	5	Screw-on Front	Rostfritt stål	Anodized	Conductive	Nej
30118-349	5	Screw-on Front	Rostfritt stål	Anodized	Conductive	Nej
30118-350	5	Screw-on Front	Rostfritt stål	Anodized	Conductive	Nej
30118-351	5	Screw-on Front	Rostfritt stål	Anodized	Conductive	Nej
30118-352	5	Screw-on Front	Rostfritt stål	Anodized	Conductive	Nej
30118-353	5	Screw-on Front	Rostfritt stål	Anodized	Conductive	Nej
30118-354	5	Screw-on Front	Rostfritt stål	Anodized	Conductive	Nej

Table 2/3						
Katalognummer	Uppfyller kraven enligt	EMC Shielding	Höjd	Material	Product Type	Rack Height
30118-348	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-349	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-350	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-351	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-352	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-353	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U
30118-354	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Aluminium	Front Panel	3 U

Table 3/3			
Katalognummer	Rack Width	Typ	Bredd

30118-348	4 HP	Front Panel without Handle	20 mm
30118-349	4 HP	Front Panel without Handle	20 mm
30118-350	4 HP	Front Panel without Handle	20 mm
30118-351	4 HP	Front Panel without Handle	20 mm
30118-352	4 HP	Front Panel without Handle	20 mm
30118-353	4 HP	Front Panel without Handle	20 mm
30118-354	4 HP	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE