


Front Panel, Flat, Unshielded, D-Sub Cutouts

Energiföretag

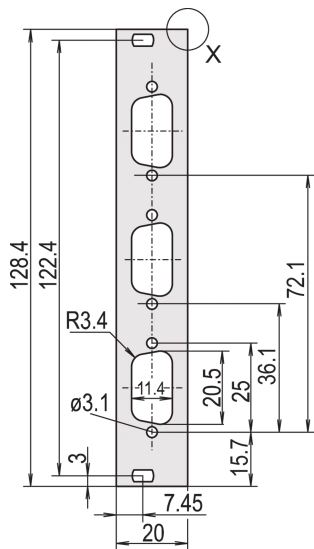

Flat front panel with cutout for D-Sub connectors.
Unshielded version.

CERTIFYING



FUNKTIONER

Non-shielded version

Aluminum, 2.5 mm, front anodized, rear conductive

SPECIFIKATIONER

Table 1/3						
Katalognummer	Package Quantity	Montering	Front Finish	Rear Finish	Treated Edges	Uppfyller kraven enligt
30118-341	5	Screw-on Front	Anodized	Conductive	Nej	IEC 60297-3-101, IEEE 1101.1/10

Katalognummer	Package Quantity	Montering	Front Finish	Rear Finish	Treated Edges	Uppfyller kraven enligt
30118-342	5	Screw-on Front	Anodized	Conductive	Nej	IEC 60297-3-101, IEEE 1101.1/10
30118-343	5	Screw-on Front	Anodized	Conductive	Nej	IEC 60297-3-101, IEEE 1101.1/10
30118-344	5	Screw-on Front	Anodized	Conductive	Nej	IEC 60297-3-101, IEEE 1101.1/10
30118-345	5	Screw-on Front	Anodized	Conductive	Nej	IEC 60297-3-101, IEEE 1101.1/10
30118-346	5	Screw-on Front	Anodized	Conductive	Nej	IEC 60297-3-101, IEEE 1101.1/10
30118-347	5	Screw-on Front	Anodized	Conductive	Nej	IEC 60297-3-101, IEEE 1101.1/10

Table 2/3

Katalognummer	EMC Shielding	Höjd	Material	Product Type	Rack Height	Rack Width
30118-341	Nej	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-342	Nej	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-343	Nej	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-344	Nej	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-345	Nej	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-346	Nej	128.4 mm	Aluminium	Front Panel	3 U	4 HP
30118-347	Nej	128.4 mm	Aluminium	Front Panel	3 U	4 HP

Table 3/3

Katalognummer	Typ	Bredd
30118-341	Front Panel without Handle	20 mm

Katalognummer	Typ	Bredd
30118-342	Front Panel without Handle	20 mm
30118-343	Front Panel without Handle	20 mm
30118-344	Front Panel without Handle	20 mm
30118-345	Front Panel without Handle	20 mm
30118-346	Front Panel without Handle	20 mm
30118-347	Front Panel without Handle	20 mm

ADDITIONAL PRODUCT DETAILS

Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE