


Front Panel, Unshielded, Bottom Hinged

Energiföretag

Unshielded front panel bottom hinged.

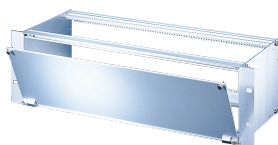

CERTIFIERING



FUNKTIONER

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

SPECIFIKATIONER

Table 1/3

Katalognummer	Rack Height	Rack Width	Package Quantity	Montering	Front Finish	Rear Finish
20838-271	3 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-272	3 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-273	3 U	84 HP	1	Hinged, Bottom	Anodized	Conductive

Katalognummer	Rack Height	Rack Width	Package Quantity	Montering	Front Finish	Rear Finish
20838-274	6 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-275	6 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-276	6 U	84 HP	1	Hinged, Bottom	Anodized	Conductive
20838-277	4 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-278	4 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-279	4 U	84 HP	1	Hinged, Bottom	Anodized	Conductive
20838-280	3 U	28 HP	1	Hinged, Bottom	Anodized	Conductive

Table 2/3

Katalognummer	Treated Edges	Uppfyller kraven enligt	EMC Shielding	Höjd	Material	Product Type
20838-271	Nej	IEC 60297-3-101, IEEE 1101.1/10	Nej	128.4 mm	Aluminium	Front Panel
20838-272	Nej	IEC 60297-3-101, IEEE 1101.1/10	Nej	128.4 mm	Aluminium	Front Panel
20838-273	Nej	IEC 60297-3-101, IEEE 1101.1/10	Nej	128.4 mm	Aluminium	Front Panel
20838-274	Nej	IEC 60297-3-101, IEEE 1101.1/10	Nej	261.8 mm	Aluminium	Front Panel
20838-275	Nej	IEC 60297-3-101, IEEE 1101.1/10	Nej	261.8 mm	Aluminium	Front Panel
20838-276	Nej	IEC 60297-3-101, IEEE 1101.1/10	Nej	261.8 mm	Aluminium	Front Panel
20838-277	Nej	IEC 60297-3-101, IEEE 1101.1/10	Nej	172.9 mm	Aluminium	Front Panel

Katalognummer	Treated Edges	Uppfyller kraven enligt	EMC Shielding	Höjd	Material	Product Type
20838-278	Nej	IEC 60297-3-101, IEEE 1101.1/10	Nej	172.9 mm	Aluminium	Front Panel
20838-279	Nej	IEC 60297-3-101, IEEE 1101.1/10	Nej	172.9 mm	Aluminium	Front Panel
20838-280	Nej	IEC 60297-3-101, IEEE 1101.1/10	Nej	128.4 mm	Aluminium	Front Panel

Table 3/3

Katalognummer	Typ	Bredd
20838-271	Front Panel without Handle	213 mm
20838-272	Front Panel without Handle	319.7 mm
20838-273	Front Panel without Handle	426.4 mm
20838-274	Front Panel without Handle	213 mm
20838-275	Front Panel without Handle	319.7 mm
20838-276	Front Panel without Handle	426.4 mm
20838-277	Front Panel without Handle	213 mm
20838-278	Front Panel without Handle	319.7 mm
20838-279	Front Panel without Handle	426.4 mm
20838-280	Front Panel without Handle	141.9 mm

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE