


E650C-G Ground Sensor for Elexant 650c-Modbus

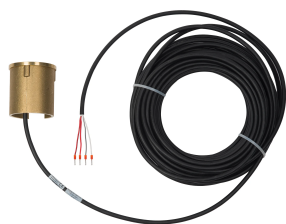

Ground sensor for combined measurement of temperature and moisture values in outdoor areas with foot or vehicle traffic. Robust version made of brass, fully encapsulated. Very low installation height, so particularly well suited to staircases, terraces, etc.

DESIGN

Cable connection: To the side

Connection cable: 4 x 0.5 mm²

Temperature range for moisture measurement: -20°C to 30°C

SPECIFIKATIONER

Table 1/2

Katalognummer	Artikelnamn	Kommunikation	Diameter	Farligt område	Höjd	IP-klassning
1244-022796	E650C-G-HOUSING	Nej	68 mm	Nej	31 mm	IP68
1244-022794	E650C-G	Nej	68 mm	Nej	72 mm	IP68

Table 2/2

Katalognummer	Artikelnamn	Mätområde
1244-022796	E650C-G-HOUSING	
1244-022794	E650C-G	-20 to 30 °C

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

Tel +1.800.545.6258

Fax +1.800.527.5703

thermal.info@nvent.com

Europe, Middle East, Africa

Tel +32.16.213.511

Fax +32.16.213.604

thermal.info@nvent.com

Asia Pacific

Tel +86.21.2412.1688

Fax +86.21.5426.3167

cn.thermal.info@nvent.com

Latin America

Tel +1.713.868.4800

Fax +1.713.868.2333

thermal.info@nvent.com

Vårt starka utbud av varumärken:

RAYCHEM PYROTENAX TRACER NUHEAT