


19" Front Panel for Cable Eyes

19" front panel are for accommodating cable eyes.

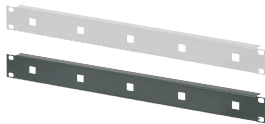

CERTIFIERINGAR



DESIGN

19" front panel to accommodate cable eyes (to mount the eyes, insert and rotate them 45°)

SPECIFIKATIONER

Djup:	1.5mm
Rackbredd:	95HP
Tillbehörstyp:	Frontpanel
Produkttyp:	Frontpanel
Material:	Stål

Table 1/2

Katalognummer	Rackhöjd	Montage	Antal i förpackningen	Främre finish	Bakre finish	Färgkod
20118-761	1U	Skrivas på front	1	Lackad	Lackad	RAL 7035
20118-762	1U	Skrivas på front	1	Lackad	Lackad	RAL 7021

Table 2/2

Katalognummer	EMC-skydd	Yta	Höjd	Typ	Bredd	Snabbleverans
20118-761	Nej	Pulverlackerad	43.6mm	19-tums frontpanel	483mm	Nej
20118-762	Nej	Pulverlackerad	43.6mm	19-tums frontpanel	483mm	Nej

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE