


VME64x System, 2 U, 4 Slot, Pluggable PSU

KATALOGNUMMER

20836-245

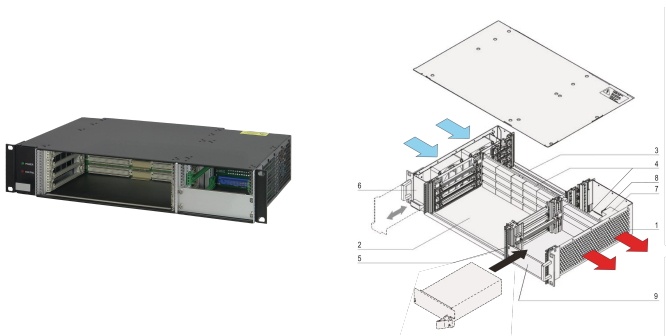

VME64x system for 4 horizontally mounted VME64x boards 6 U, 160 mm. Rear I/ O option. The power for the system is supplied by up to two pluggable power supplies. A hot swap fan tray with 4 fans guarantee an excellent cooling.

CERTIFIERINGAR



DESIGN

System in accordance with IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; backplane conforms to VITA 1.1-1997

Power backplane to PICMG 2.11 (P 47), prepared for installation of two 19" compatible PSUs, 300 W (3 U, 8 HP)

Heat dissipation by a fan tray with 2 fans, cooling from right to left side; fan monitoring and voltage display

System for horizontal board mounting with board formats; Front: 6 U, 160 mm deep; Rear, rear I/O: 6 U, 80 mm deep

PRODUKTATTRIBUT

Produkttyp: System

Antal fack: 4

Typ: 19 tums rackfäste

Bakplanstyp: 6 U VME64-förlängning

Dataöverföring: VME64; VME2eSST

Effekt per fack: 30W

Ingångsspänning AC: 100 – 240V

Luftflödesriktning: Vänster till höger

Rackhöjd: 2U

Strömförsörjningstyp: (2) PSU som är möjlig att plugga

Strömförsörjning inkluderad: Nej

Bakre I/O: Ja

Uppfyller: ANSI/VITA 1.1-1997

Djup: 277.5mm

Höjd: 88.1mm

Bredd: 449mm

Antal i förpackningen: 1

YTTERLIGARE PRODUKTINFORMATION

Modified systems available on request.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE