


VME64x System, 7 U, 12 Slot, Open Frame PSU

KATALOGNUMMER

20836-717

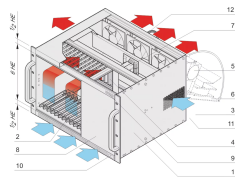

VME64 system for 12 VME64x boards 6 U, 160 mm. The power for the system is supplied by an open frame power supply. A fan control module monitors the fans, the temperature and voltage.

CERTIFIERINGAR



DESIGN

System in accordance with IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; backplane conforms to VITA 1.1-1997

PSU, open frame, 642 W (600 W at < 180 VAC)

Backplane VME64x 12 slot, 6 U, J1/J2 monolithic without P0 connector, in accordance with VITA 1-1994 and 1.1-1997

Heat dissipation by 3 fans assembled to the rear panel, cooling from front to rear side; temperature-controlled by fan control module (FCM)

System for standard board mounting with board format, 6 U, 160 mm deep

Display module for DC operating voltages, fan and temperature alarm

PRODUKTATTRIBUT

Produkttyp: System

Antal fack: 12

Typ: 19 tums rackfäste

Bakplanstyp: 6 U VME64-förlängning

Dataöverföring: VME64; VME2eSST

Effekt per fack: 30W

Ingångsspänning AC: 100 – 240V

Luftflödesriktning: Front till bakdel

Rackhöjd: 7U

Strömförsörjningstyp: Öppen ram

Strömförsörjning inkluderad: Ja

Bakre I/O: Ja

Uppfyller: ANSI/VITA 1.1-1997

Djup: 355mm

Höjd: 310.35mm

Bredd: 449mm

Effekt: 450W

Antal i förpackningen: 1

YTTERLIGARE PRODUKTINFORMATION

Modified systems available on request.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplikering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE