


Quarter-Turn Fastener With Knurled and Slotted Head, Grey; 100 pieces

KATALOGNUMMER

21101-849

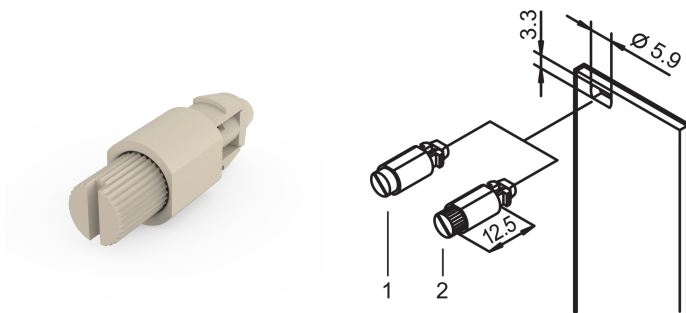

1/4 rotary lock with defined stop.

CERTIFIERINGAR



DESIGN

1/4 rotary lock with defined stop

Identification of locking position due to slot position

Vibration and shake proof

Qty 100 pieces

PRODUKTATTRIBUT

Färg: Pebble Grey

Antal i förpackningen: 100

Färgkod: RAL 7032

Djup: 20.6mm

Yta: Förtennad

Höjd: 6mm

Material: Stål; Zinklegering; Termoplast

Produkttyp: Beslagsats

Bredd: 7mm

Fungerar med: Frontpaneler

Fästdonstyp: Räfflad; Slotted Head

YTTERLIGARE PRODUKTINFORMATION

Quick-release fasteners: mounting without threaded inserts.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE