


CPCI PlusIO System With Pluggable PSU, 4 U, 8 Slot

KATALOGNUMMER

24579-400

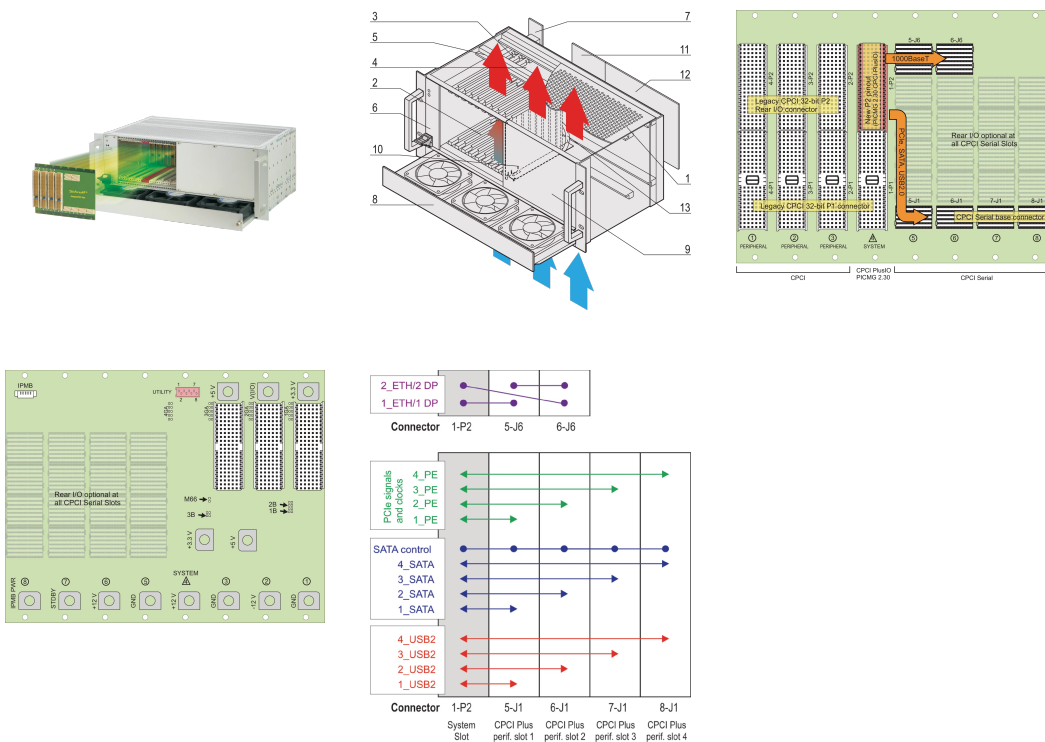

4 U CompactPCI PlusIO System with vertical Card Cage for one CPCI PlusIO System Controller, 4 CompactPCI and 3 CompactPCI Serial Peripheral Boards and one CompactPCI 3 U Pluggable Power Supply.

CERTIFIERINGAR



DESIGN

In accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; backplane in accordance with PICMG 2.0 rev. 3.0 and PICMG 2.30 rev. 1.0

System with vertical card cage. Board format Front: 3 U, 160 mm deep, 8 slot; Rear I/O: 3 U, 80 mm deep, 3 slot

Backplane 4 slot, 3 U, 32 bit, CompactPCI; 4 slot, 3 U, CompactPCI PlusIO

Heat dissipation by 1 U hot-swap fan unit, airflow bottom to top

19"-compatible PSU, 250 W, 3 U, 8 HP

Option to mount a hard disk

PRODUKTATTRIBUT

Produkttyp: System

Antal fack: 8

Typ: 19 tums rackfäste

Bakplanstyp: 3 U, 4-facks CompactPCI och 4-facks CompactPCI, seriell

Dataöverföring: 32-bitars PCI-buss; PCIe Gen2

Effekt per fack: 40W

Ingångsspänning AC: 100 – 240V

Luftflödesriktning: Underdel till överdel

Rackhöjd: 4U

Strömförsörjningstyp: (1) PSU som är möjlig att plugga

Strömförsörjning inkluderad: Ja

Bakre I/O: Ja

Uppfyller: PICMG 2.30 R1.0

Djup: 275mm

Höjd: 177mm

Antal i förpackningen: 1

YTTERLIGARE PRODUKTINFORMATION

Modified systems available on request.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE