


Varistar CP Top Cover Fan, Energy Efficient, Height 38 mm, 171 m³/h

KATALOGNUMMER

24630-117

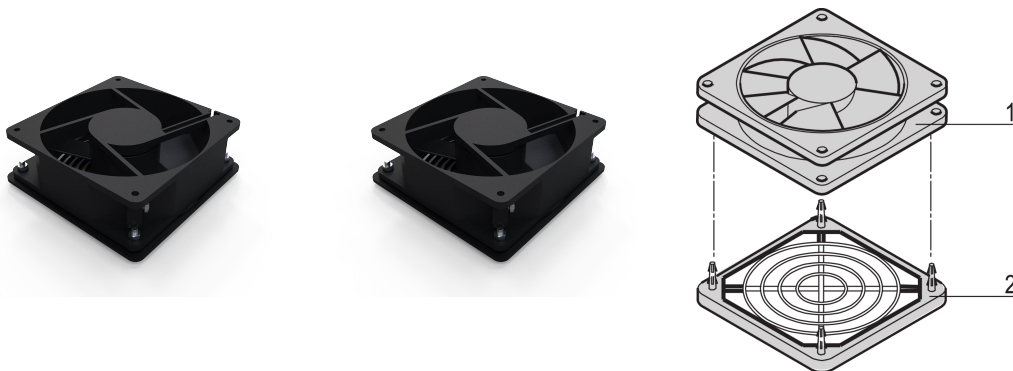

Top covers with fans are compact active cooling units which do not consume rack space. The Varistar fan for top cover comes with high specifications.

DESIGN

Varistar Top Cover Fan, Height 38 mm, 171 m³/h

PRODUKTATTRIBUT

Produkttyp: Fläkt

Produktfamilj: Varistar CP

Fungerar med: Varistar CP

Djup: 119mm

Bullernivå: 42.5dB(A)

Effekt: 9.6W

Max. statiskt tryck: 68.1Pa

Luftflöde vid 50 Hz: 171m³/h

Yta: Pulverlackerad

Höjd: 38mm

Ingångsspänning AC: 18 – 27.6V

Material: Stål

Antal i förpackningen: 1

Bredd: 119mm

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE