
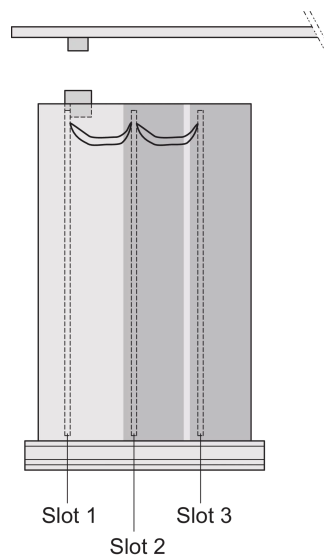
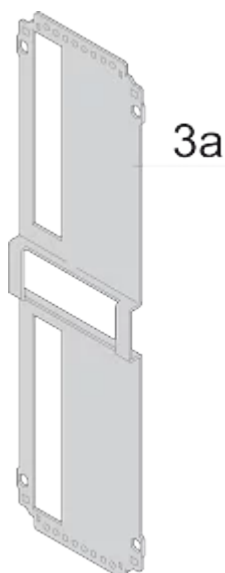
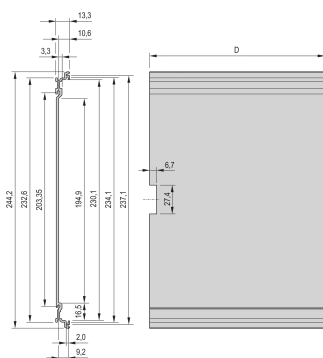
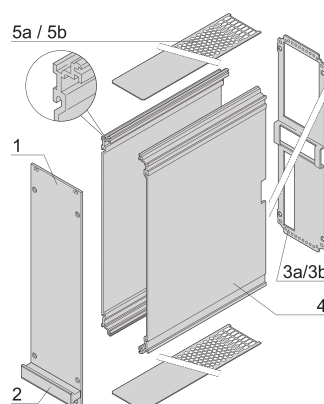


Typ av insticksenhet PRO Kit, perforerade kåpor, 1 Kontakt, 6 U, 14 HP, 227 mm

KATALOGNUMMER

24812-764

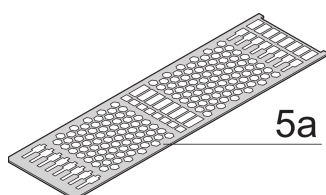

Frame type plug-in unit, non-shielded, perforated top / bottom cover, rear panel with cutout for one connector.

CERTIFIERINGAR



DESIGN

Extruded side panels right and left, with grooves for insertion of a printed circuit board (standard board position is on the left only)

Rear panel with cut-out for single connector (conforms to EN 60603, DIN 41612, construction types: B, C, D, F, H, Q, R, S)

Cover plate with perforation, for guide rails (airflow approx. 60%); please order guide rails separately

PRODUKTATTRIBUT

Rackhöjd: 6U

Rackbredd: 14HP

Antal i förpackningen: 1

Handtagstyp: Trapets

Typ av bakpanel: Utskärning för en kontakt

Täckplatta, typ: Täckplatta med perforering för styrskenor

Främre finish: Anodiserad

Bakre finish: Anodiserad

Kylning: Perforerad

Djup (D): 227mm

EMC-skydd: Nej

Yta: Anodiserad

Material: Aluminium


Produkttyp: Kassett

Typ: Plugin-enheter av ramtyp PRO

YTTERLIGARE PRODUKTINFORMATION

To fit further boards without rear connector, guide rail (part no. 24812-301) and 'Board fixing from slot 2' (part no. 24812-301 + screw part no. 24560-178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and one slot 2 are already included.

DIAGRAMS

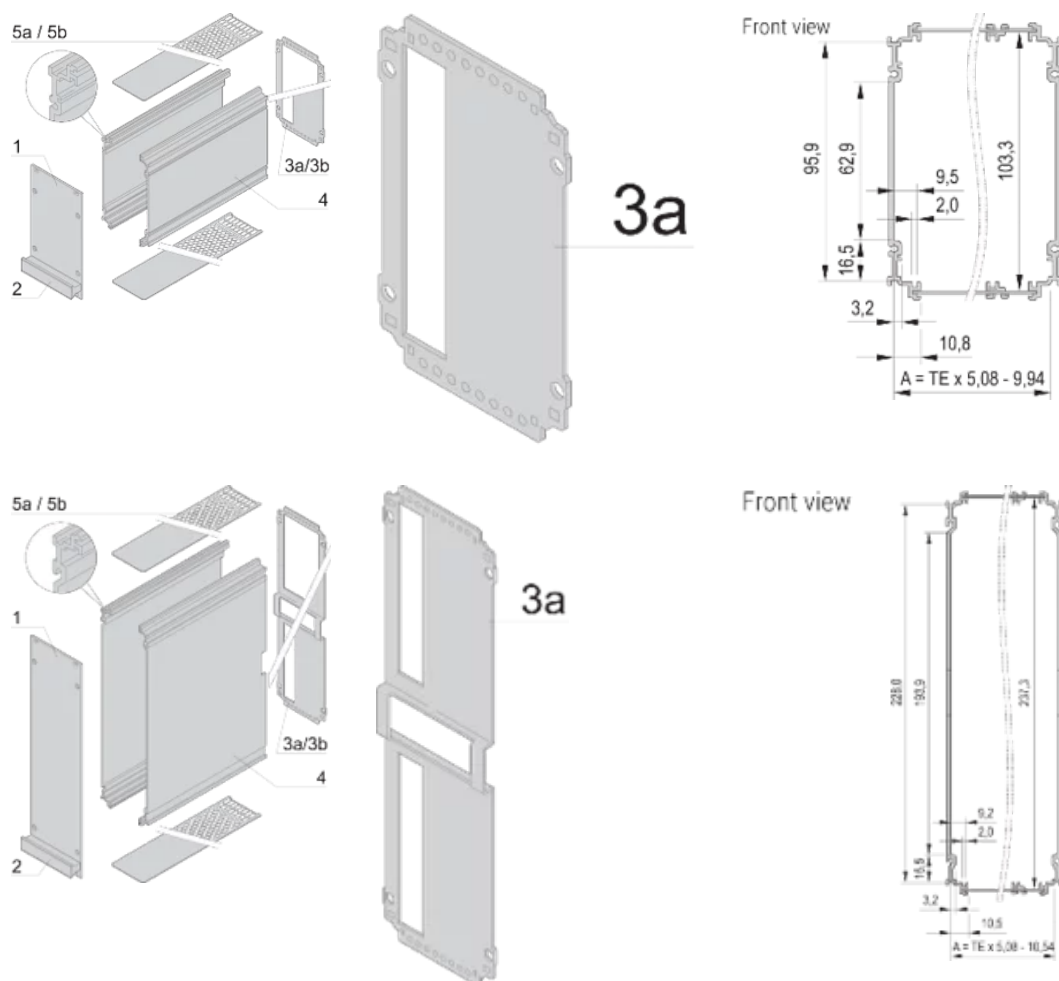

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister,

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE