


Frame Type Plug-In Unit PRO Kit, Shielded, Perforated, 1 Connector, 3 U, 14 HP, 167 mm

KATALOGNUMMER



24813-214



3 U Front panel shieldable

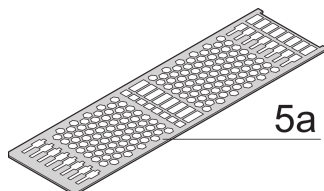

5a

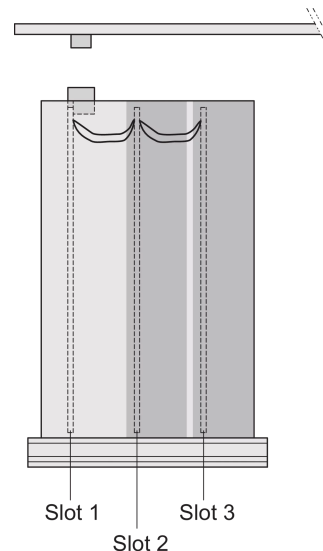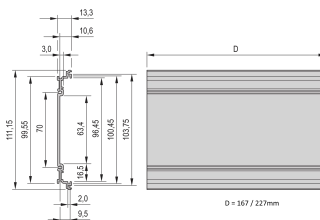

Protects a PCB against mechanical damage and discharges electrostatic buildup; for Euroboard formats; pair panel with one cutout for one connector.



DESIGN

Cover plate with perforation, for guide rails (airflow approx. 60 %)

Rear panel with cut-out for single connector (conforms to EN 60603, DIN 41612, construction types: B, C, D, F, H, Q, R, S)

Extruded side panels with groove to right and left, to insert a PCB (board position in accordance with standard in left side panel only)

PRODUKTATTRIBUT

Rackhöjd: 3U

Rackbredd: 14HP

Djup (D): 167mm

Handtagstyp: Trapets

Antal i förpackningen: 1

EMC-packningstyp: Textil

Typ av bakpanel: Utskärning för en kontakt

Täckplatta, typ: Täckplatta med perforering för styrskenor

Främre finish: Anodiserad

Bakre finish: Ledande

Kylning: Perforerad

EMC-skydd: Ja

Yta: Anodiserad; Passiverad

Material: Aluminium

Produktyp: Kassett


Typ: Plugin-enheter av ramtyp PRO

YTTERLIGARE PRODUKTINFORMATION

To fit further boards without rear connector, guide rail (part no. 24812-301) and 'Board fixing from slot 2' (part no. 24812-301 + screw part no. 24560-178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and one slot 2 are already included.

Please order guide rails separately.

DIAGRAMS

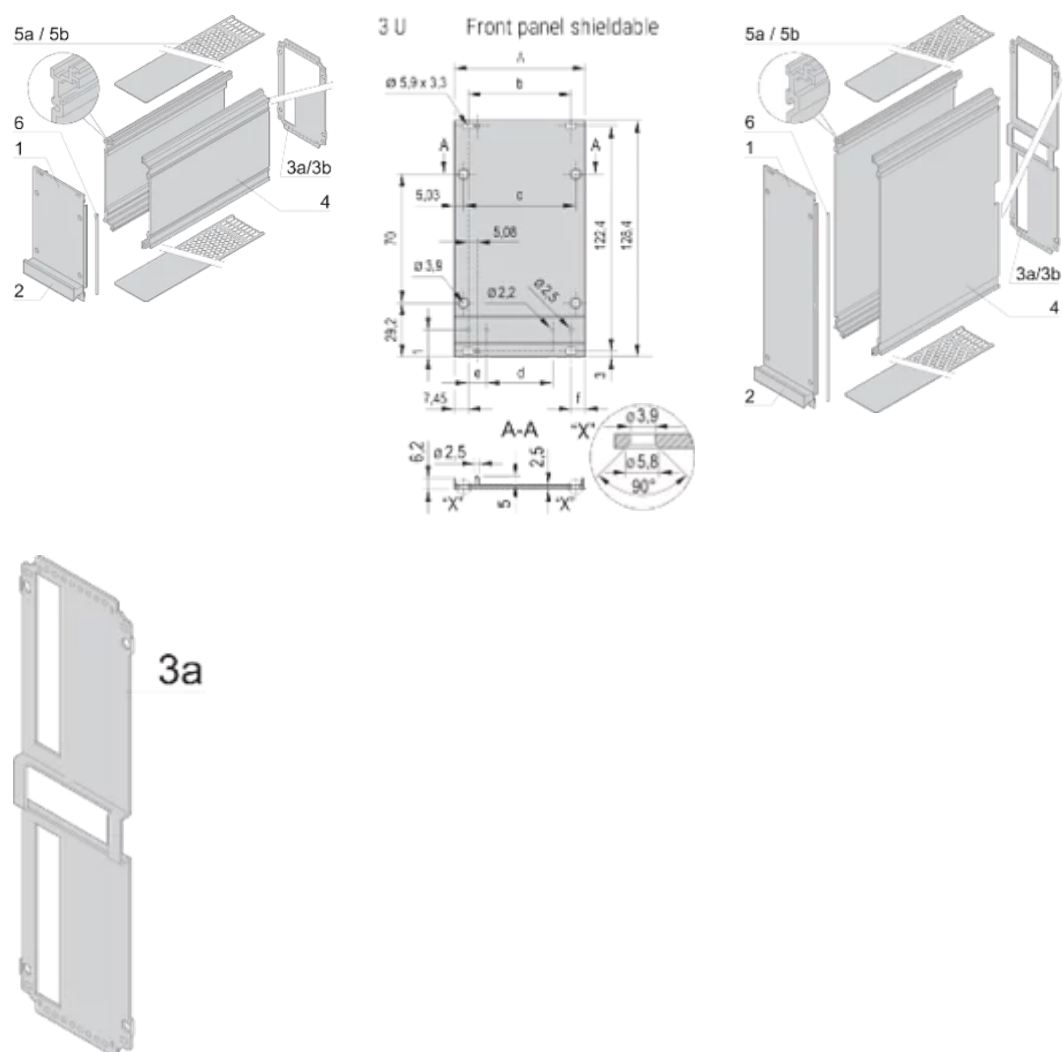

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE