


Front Panel, Unshielded, Cutout for Coax Connectors, 2.5 mm, Al, Front Anodized, Rear Conductive

KATALOGNUMMER

30118-355

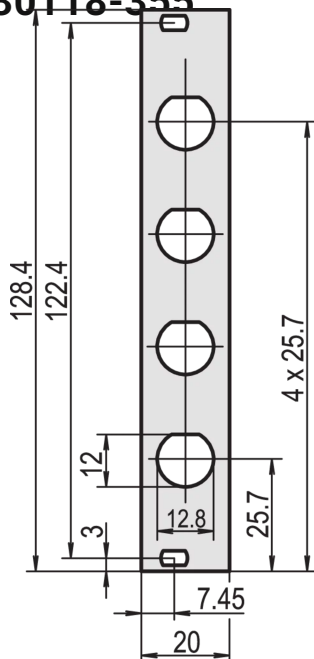

Aluminium, 2,5 mm, främre anodiserad, ledande, oskärmad version.

CERTIFIERINGAR



DESIGN

Al, 2,5 mm, främre anodiserad, ledande

3 U, 4 HK

PRODUKTATTRIBUT

Produkttyp: Frontpanel

Typ: Frontpanel utan handtag

Tillbehörstyp: Frontpanel

Montage: Skruvfront

EMC-skydd: Nej

Material: Aluminium

Främre finish: Anodiserad

Bakre finish: Ledande

Behandlade kanter: Nej

Rackhöjd: 3U

Höjd (H): 128.4mm

Rackbredd: 4HP

Bredd (W): 19.98mm

Djup (D): 2.5mm

Uppfyller: IEC 60297-3-101; IEEE 1101.1/10


Antal i förpackningen: 1

Yta: Anodiserad; Passiviserade

YTTERLIGARE PRODUKTINFORMATION

Beställ monteringsmaterial (hylsor, flänsskruvar) separat.

DIAGRAMS

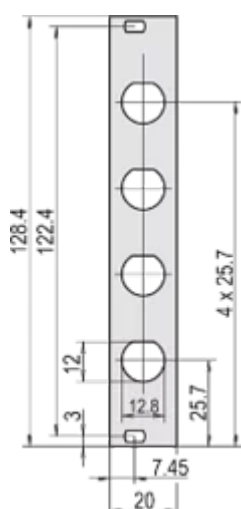

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation,

missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE