


19" Front Panel, 1 U, 3 mm, Al, Anodized, Untreated Edges

KATALOGNUMMER

30219-098

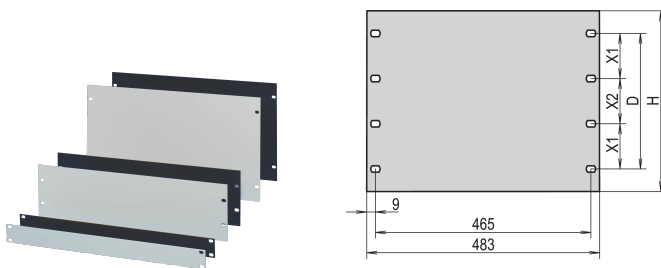

Front panels made of Aluminum.

CERTIFIERINGAR



DESIGN

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

PRODUKTATTRIBUT

Rackhöjd: 1U

Djup (D): 3mm

Tillbehörstyp: Frontpanel

Montage: Skruvas på front

Yta: Anodiserad

Främre finish: Anodiserad

Antal i förpackningen: 1

Bakre finish: Anodiserad

Behandlade kanter: Nej

EMC-skydd: Nej

Höjd (H): 43.6mm

Material: Aluminium

Produkttyp: Frontpanel

Rackbredd: 95HP


Typ: 19-tums frontpanel

Bredd (W): 483mm

YTTERLIGARE PRODUKTINFORMATION

Please order 19" assembly kit separately.

DIAGRAMS

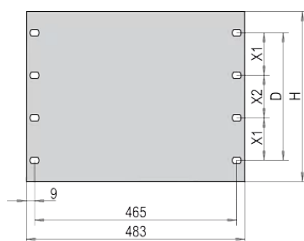

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE