
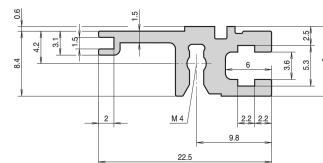


Horisontell skena, bak, typ L-ST, ljus, standard, 20 HP

KATALOGNUMMER

34560-420

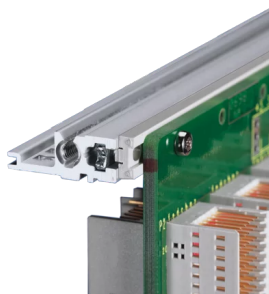

Combinations of horizontal rails and side panels

		+ = can be combined				- = combination not recommended	
Light + B		-	+	+	+	Light + B (sag)	
Heavy + B		+	network kit flexible (no sag)	network kit Heavy and Heavy Duty (no sag)	+	Light + B (sag)	
Light + L		network kit Light	network kit flexible	-	-	Light + L (sag)	
Heavy + L		+	+	-	-	Light + L (sag)	
Horizontal (all)						Horizontal (all)	
Side panel						Side panel	

Den horisontella skenan av typ ST möjliggör isolerad montering av ett bakplan. Isoleringen görs med en isoleringsremsa.

CERTIFIERINGAR



DESIGN

För indirekt bakplansmontering med isoleringslist

Montering upptill och nedtill

Aluminium extrudering, anodiserad yta, ledande kontaktyta

PRODUKTATTRIBUT

Rackbredd: 20HP

Förpackningskvantitet: 1

Slutför: Anodiserad

Längd: 106.68mm

Material: Aluminium

Produktfamilj: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Produkttyp: Horisontell skena

Typ: Ljus, ST

Fungerar med.: Underrack; Fall

Net Weight: 0.024kg

YTTERLIGARE PRODUKTINFORMATION

Leverans sker i standardpaket. Priset är per enskild artikel.

Tänk på att leveranser kan utföras i angivna SPQ (SPQ, t.ex. 5 stycken, 10 stycken, 50 stycken, etc.). Olika orderkvantiteter (t.ex. 2 stycken) kan ändras till nästa möjliga leveranskvantitet = Standardförpackningskvantitet.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE