


Horisontell skena, fram, typ R-LD, robust, låg kant , 28 hk

KATALOGNUMMER

34566-328

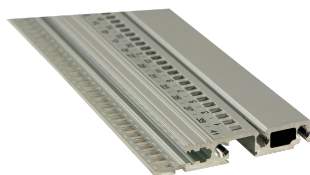

Combinations of horizontal rails and side panels

	 Rail 1.0	 Rail 2.0	 Rail 3.0	 Rail 4.0
 Panel 1.0	 + can be combined	 + combination not recommended	 + combination not recommended	 + not supported
 Panel 2.0	 +	 + not supported for panel with 20mm depth	 + combination not recommended	 +
 Panel 3.0	 + not supported	 + not supported	 +	 +
 Panel 4.0	 +	 +	 +	 +

 Rail 1.0
  Rail 2.0
  Rail 3.0
  Rail 4.0

 Panel 1.0
  Panel 2.0
  Panel 3.0
  Panel 4.0

Den robusta horisontella skentypen kan hantera stötar och vibrationer upp till 25 g. det möjliggör användning av IEEE-handtag.

CERTIFIERINGAR



DESIGN

Robusta horisontella skenor av typ R-LD med 3-håls infästning för ökad robusthet

För insättning/extraktion av CompactPCI- eller VME64x-kort

Med HP-enheter tryckta från 28 HP och uppåt

Längd 20, 28, 40, 42, 63, 84 HP eller 1000 mm

Extrudering av aluminium, anodiserad yta, ledande kontaktyta, med HP-märkning

PRODUKTATTRIBUT

Rackbredd: 28HP

Förpackningskvantitet: 1

Slutför: Anodiserad

Längd: 147.32mm

Material: Aluminium

Produktfamilj: EuropacPRO

Produkttyp: Horisontell skena

Typ: Robust, LD

Fungerar med.: Underrack

Net Weight: 0.09kg

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE