 


EuropacPRO 19" Subrack Kit for Backplane, Heavy, Shielded

EMC Shielded subrack for backplane mounting, heavy version with tox welded side panels.



CERTIFIERINGAR



DESIGN

Subrack with side panel type H ("Heavy"), 19" bracket is firmly fixed to side panel (tox-cold welded)

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

Rear horizontal rail for backplane mounting with insulation strip

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Shock and vibration tested to the German "Bahn" standards BN 411002, BN 411003

IP 20, in accordance with IEC 60529

SPECIFIKATIONER

Material: Aluminium

Yta: Anodiserad; Passiverad

Produkttyp: Underrack/chassi

EMC-skydd: Ja

Table 1/3

Katalognummer	Rackhöjd	Djup (D)	Antal i förpackningen	För montering	Kortdjup	EMC-packningstyp
24563-172	3U	235mm	1	Bakplan	160mm, 220mm	Textil
24563-173	3U	295mm	1	Bakplan	160mm, 220mm, 280mm	Textil
24563-174	3U	355mm	1	Bakplan	160mm, 220mm, 280mm	Textil
24563-472	6U	235mm	1	Bakplan	160mm, 220mm	Textil
24563-473	6U	295mm	1	Bakplan	160mm, 220mm, 280mm	Textil
24563-474	6U	355mm	1	Bakplan	160mm, 220mm, 280mm	Textil

Table 2/3

Katalognummer	Stöt- och vibrationstolerans	Handtag ingår	Montage	Uppfyller	Rackbredd	Statisk belastning
24563-172	5g (force)	Nej	Rack	IEC 60297-3-103	84HP	15kg
24563-173	5g (force)	Nej	Rack	IEC 60297-3-103	84HP	15kg
24563-174	5g (force)	Nej	Rack	IEC 60297-3-103	84HP	15kg
24563-472	5g (force)	Nej	Rack	IEC 60297-3-103	84HP	15kg
24563-473	5g (force)	Nej	Rack	IEC 60297-3-103	84HP	15kg
24563-474	5g (force)	Nej	Rack	IEC 60297-3-103	84HP	15kg

Table 3/3


Katalognummer	Snabbleverans
---------------	---------------

24563-172	Nej
24563-173	Nej
24563-174	Nej
24563-472	Nej
24563-473	Nej
24563-474	Nej

YTTERLIGARE PRODUKTINFORMATION

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

DIAGRAMS

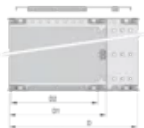

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE