


EuropacPRO 19" Subrack Kit for Railway, Retrofit Shielding, EN 50155

Subrack for Railway applications, conform to EN50155 standard, non-shielded.

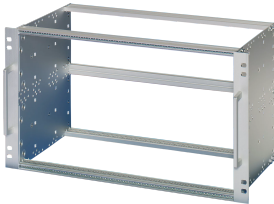

CERTIFIERINGAR



DESIGN

Shock and vibration tested to EN 50155, part 12.2.11

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Modifications such as cutouts, different finishes or dimensions available

IP 20, in accordance with IEC 60529

The double 19" screwing position adds to additionally safety (NFF standard)

Supplied as space-saving flat-pack

SPECIFIKATIONER

Statisk belastning:	15kg
Material:	Aluminium
EMC-skydd:	Nej
Produkttyp:	Underrack/chassi

Table 1/3

Katalognummer	Rackhöjd	Djup	Antal i förpackningen	För montering	Kortdjup	EMC-packningstyp
21500-077	3U	235mm	1	Bakplan	220mm	Textil
21500-078	6U	235mm	1	Bakplan	220mm	Textil

Table 2/3

Katalognummer	Stöt- och vibrationstolerans	Handtag ingår	Montage	Uppfyller	Yta	Rackbredd
21500-077	5g (force)	Ja	Rack	IEC 60297-3-103, EN 50155 del 12.2.11	Anodiserad, Passiverad	84HP
21500-078	5g (force)	Ja	Rack	IEC 60297-3-103, EN 50155 del 12.2.11	Anodiserad, Passiverad	84HP

Table 3/3

Katalognummer	Snabbleverans
21500-077	Nej
21500-078	Nej

YTTERLIGARE PRODUKTINFORMATION

Test reports are available online.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE