


# Front Panel, Flat, Refrofit Shielding, D-Sub Cutouts

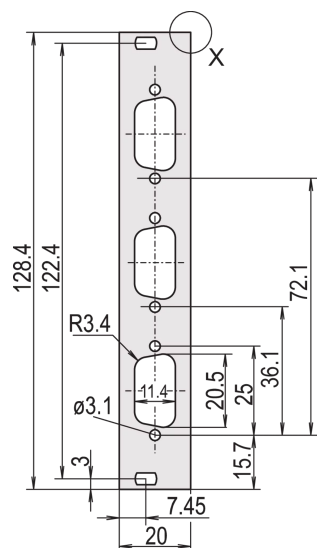

Flat front panel with cutout for D-Sub connectors.  
Shieldable for stainless steel EMC gasket.

## CERTIFIERINGAR



## DESIGN

For stainless steel EMC gasket

Al, 2.5 mm, front anodized, conductive

## SPECIFIKATIONER

|                       |                        |
|-----------------------|------------------------|
| <b>Rackhöjd:</b>      | 3U                     |
| <b>Rackbredd:</b>     | 4HP                    |
| <b>Material:</b>      | Aluminium              |
| <b>Yta:</b>           | Anodiserad; Passiverad |
| <b>Tillbehörstyp:</b> | Frontpanel             |
| <b>Produkttyp:</b>    | Frontpanel             |

**Typ:** Frontpanel utan handtag  
**EMC-skydd:** Nej (kan eftermonteras)

Table 1/2

| Katalognummer | Antal i förpackningen | Montage          | EMC-packningstyp | Främre finish | Bakre finish | Antal stift |
|---------------|-----------------------|------------------|------------------|---------------|--------------|-------------|
| 30118-348     | 1                     | Skrivas på front | Rostfritt stål   | Anodiserad    | Ledande      | (1) 9       |
| 30118-349     | 1                     | Skrivas på front | Rostfritt stål   | Anodiserad    | Ledande      | (1) 15      |
| 30118-350     | 1                     | Skrivas på front | Rostfritt stål   | Anodiserad    | Ledande      | (1) 25      |
| 30118-351     | 1                     | Skrivas på front | Rostfritt stål   | Anodiserad    | Ledande      | (2) 9       |
| 30118-352     | 1                     | Skrivas på front | Rostfritt stål   | Anodiserad    | Ledande      | (2) 15      |
| 30118-353     | 1                     | Skrivas på front | Rostfritt stål   | Anodiserad    | Ledande      | (2) 25      |
| 30118-354     | 1                     | Skrivas på front | Rostfritt stål   | Anodiserad    | Ledande      | (3) 9       |

Table 2/2

| Katalognummer | Behandlade kanter | Uppfyller                       | Djup (D) | Höjd (H) | Bredd (W) | Snabbleverans |
|---------------|-------------------|---------------------------------|----------|----------|-----------|---------------|
| 30118-348     | Nej               | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm    | 128.4mm  | 19.98mm   | Nej           |
| 30118-349     | Nej               | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm    | 128.4mm  | 19.98mm   | Nej           |
| 30118-350     | Nej               | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm    | 128.4mm  | 19.98mm   | Nej           |
| 30118-351     | Nej               | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm    | 128.4mm  | 19.98mm   | Nej           |
| 30118-352     | Nej               | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm    | 128.4mm  | 19.98mm   | Nej           |
| 30118-353     | Nej               | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm    | 128.4mm  | 19.98mm   | Nej           |

| Katalognummer | Behandlade kanter | Uppfyller                       | Djup (D) | Höjd (H) | Bredd (W) | Snabbleverans |
|---------------|-------------------|---------------------------------|----------|----------|-----------|---------------|
| 30118-354     | Nej               | IEC 60297-3-101, IEEE 1101.1/10 | 2.5mm    | 128.4mm  | 19.98mm   | Nej           |

## YTTERLIGARE PRODUKTINFORMATION


Please order fixing material (sleeves, collar screws) separately.


Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## DIAGRAMS

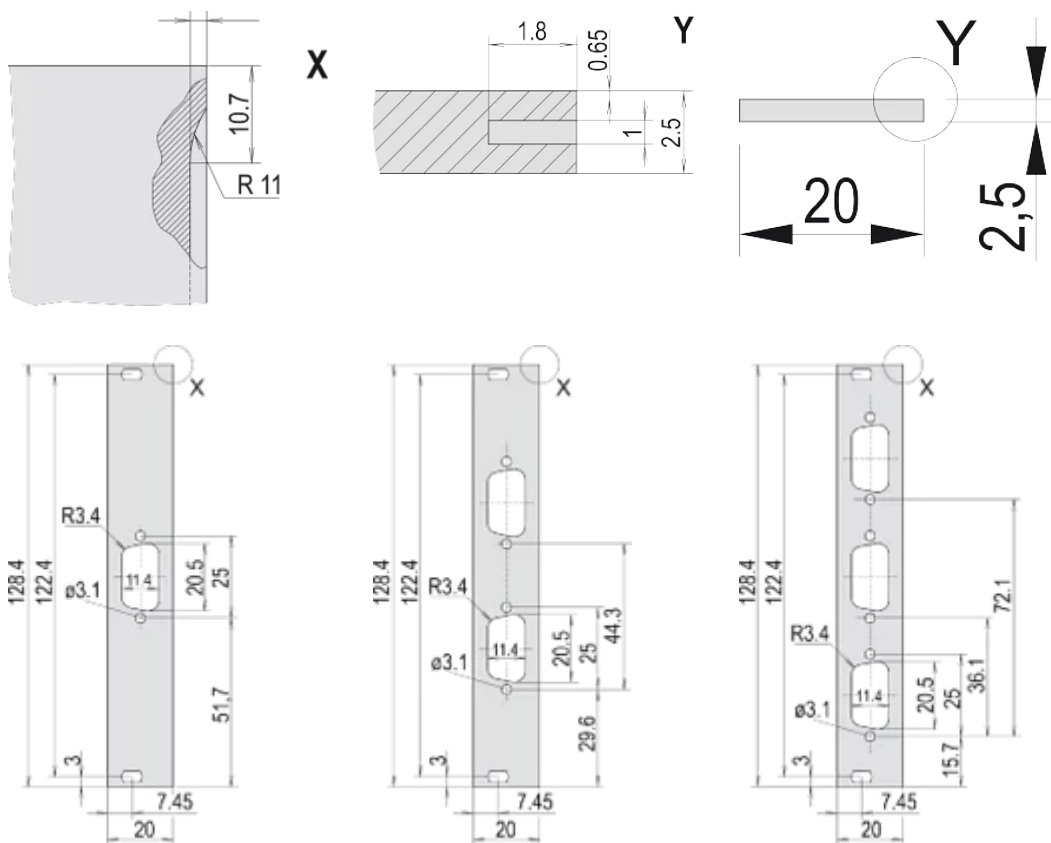

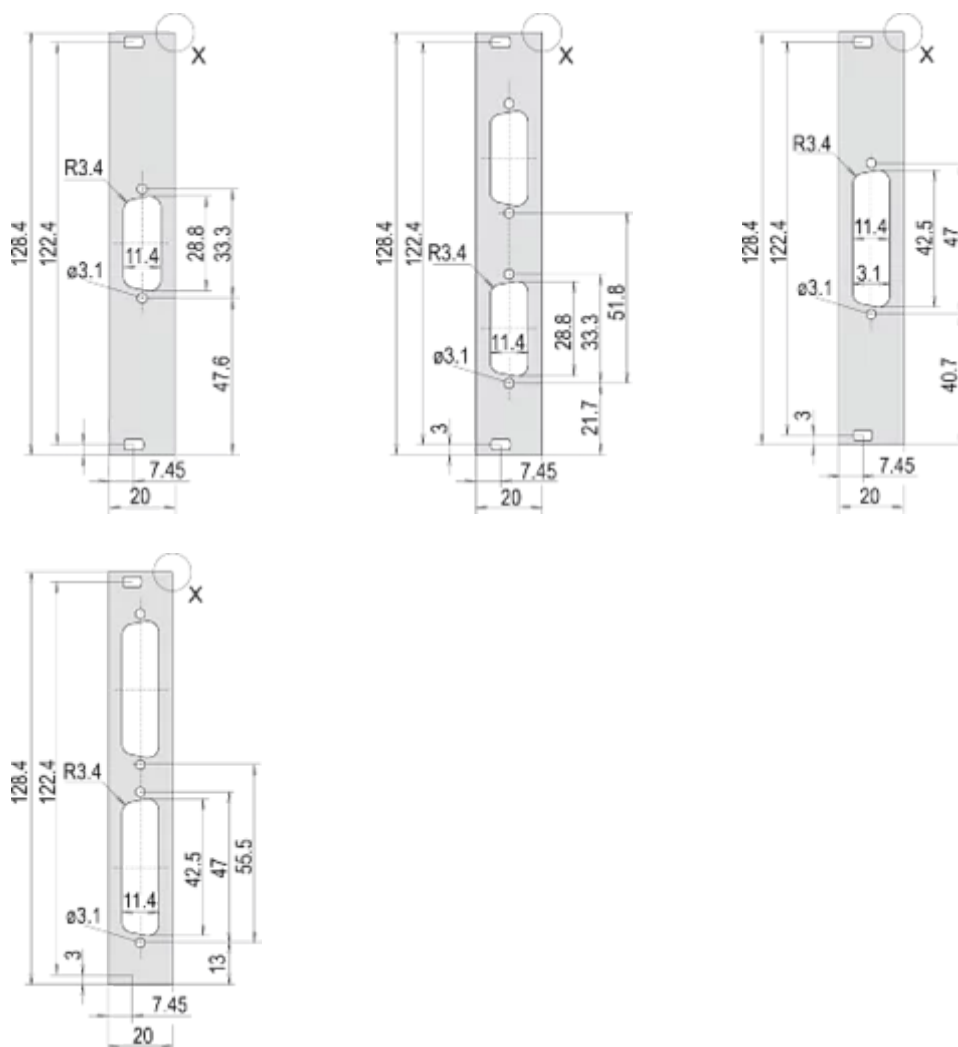

## VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på [www.nvent.com](http://www.nvent.com) och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, brandfaror och skador på egendom och miljö.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vårt starka utbud av varumärken:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**