

Front Panel, Flat, Unshielded, D-Sub Cutouts



Flat front panel with cutout for D-Sub connectors.
Unshielded version.

CERTIFIERINGAR



DESIGN

Non-shielded version

Al, 2.5 mm, front anodized, rear conductive

SPECIFIKATIONER

Rackhöjd:	3U
Rackbredd:	4HP
Material:	Aluminium
Yta:	Anodiserad; Passiverad
Tillbehörstyp:	Frontpanel
Produkttyp:	Frontpanel
Typ:	Frontpanel utan handtag

Table 1/2

Katalognummer	Antal i förpackningen	Montage	Främre finish	Bakre finish	Antal stift	Behandlade kanter
30118-341	1	Skrivas på front	Anodiserad	Ledande	(3) 9	Nej
30118-342	1	Skrivas på front	Anodiserad	Ledande	(1) 15	Nej
30118-343	1	Skrivas på front	Anodiserad	Ledande	(1) 25	Nej
30118-344	1	Skrivas på front	Anodiserad	Ledande	(2) 9	Nej
30118-345	1	Skrivas på front	Anodiserad	Ledande	(2) 15	Nej
30118-346	1	Skrivas på front	Anodiserad	Ledande	(2) 25	Nej
30118-347	1	Skrivas på front	Anodiserad	Ledande	(3) 9	Nej

Table 2/2

Katalognummer	Uppfyller	Djup (D)	EMC-skydd	Höjd (H)	Bredd (W)	Snabbleverans
30118-341	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Nej	128.4mm	19.98mm	Nej
30118-342	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Nej	128.4mm	19.98mm	Nej
30118-343	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Nej	128.4mm	19.98mm	Nej
30118-344	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Nej	128.4mm	19.98mm	Nej
30118-345	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Nej	128.4mm	19.98mm	Nej
30118-346	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Nej	128.4mm	19.98mm	Nej
30118-347	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Nej	128.4mm	19.98mm	Nej


YTTERLIGARE PRODUKTINFORMATION


Delivery is in standard pack multiples. Pricing is per individual item.

Please order fixing material (sleeves, collar screws) separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

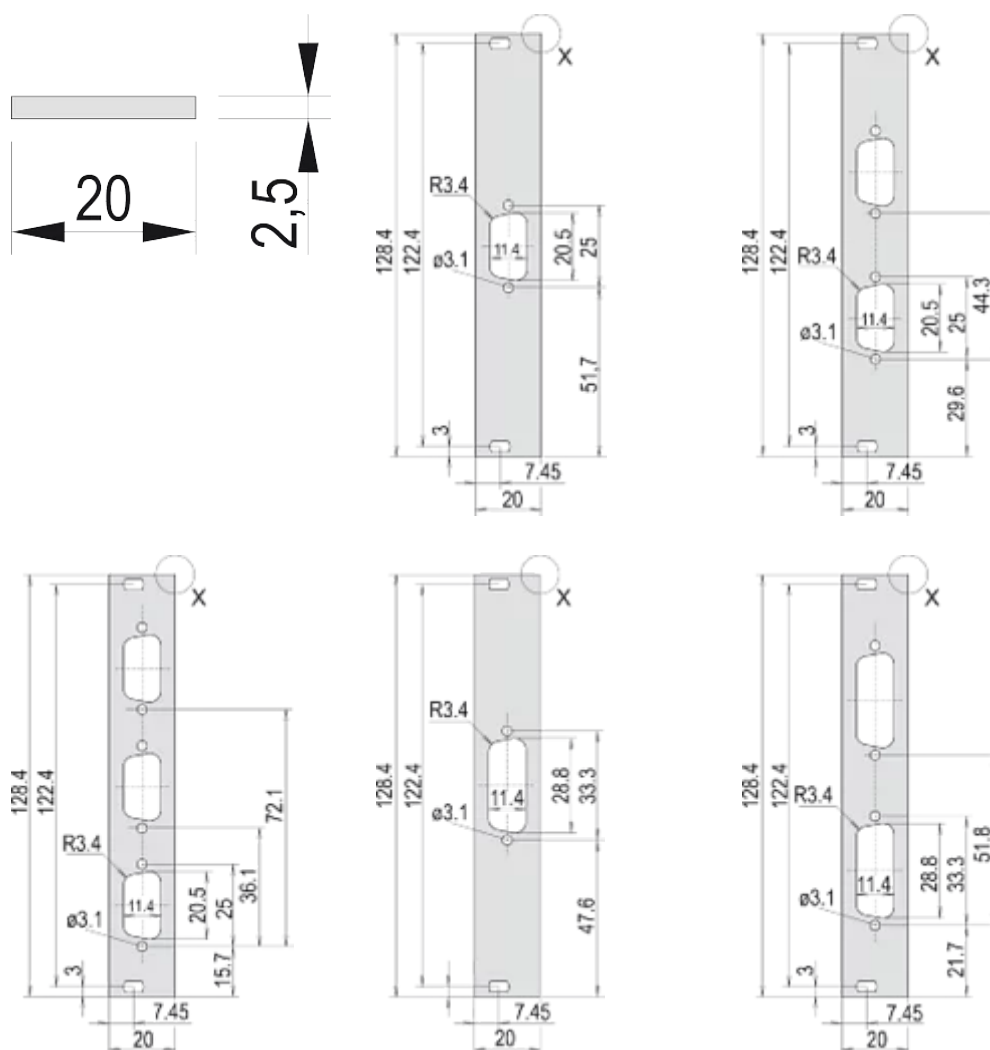

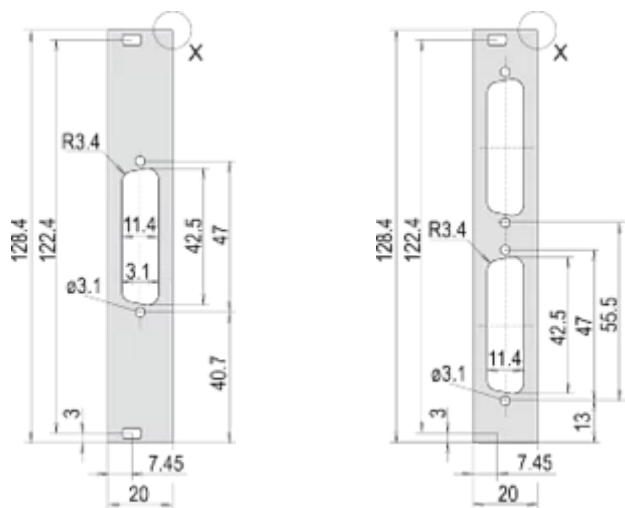

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE