


Guide Rail With Coding for CompactPCI/ VME64x, PC

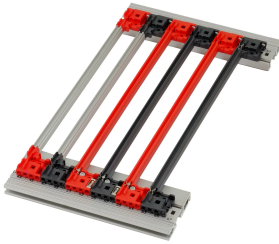

New generation of Wih Coding type guide rails for PCBs or plug-in units. Forms a reliable interface between the subrack mechanics and the sub-assemblies. With the optimized design and the new high quality plastic material not just the stability was significantly increased, but also the fire safety properties improved. Which means the material ensures a low flammability, low smoke toxicity and density and fulfills the EN 45545-2 (Fire Safety in Railway Vehicle) requirements sets R22, R23 and R24 with the

CERTIFIERINGAR



DESIGN

NEW generation with coding type plastic guide rails for reliable retention of PCBs or plug-in units

Significantly increased stability, due to a optimized design and high quality material (PC)

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

"Halogen-Free", according to IEC 61249-2-21

Can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Can be bolted to the horizontal rails Type H and R for higher shock and vibration requirements

Optional ESD clip for an conductive contact between PCB and horizontal rail available

Storage temperature: from -40 °C ... 130 °C

SPECIFIKATIONER

Fungerar med:	Underrack; Lådor; 19-tums chassi; System
Typ:	Kodning
Produktfamilj:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Produkttyp:	Styrskena

Table 1/2

Katalognummer	Material	Färg	Antal i förpackningen	Kortdjup	Spårbredd	Uppfyller
64568-089	Fiberförstärkt plast	Röd	1	160mm	2	EN 45545-2
64568-090	Fiberförstärkt plast	Grå	1	160mm	2	EN 45545-2
64568-085	Fiberförstärkt plast	Röd	1	70mm	2	EN 45545-2
64568-086	Fiberförstärkt plast	Grå	1	70mm	2	EN 45545-2
64568-091	Fiberförstärkt plast	Röd	1	220mm	2	EN 45545-2
64568-092	Fiberförstärkt plast	Grå	1	220mm	2	EN 45545-2
64568-111	Fiberförstärkt plast, Aluminium	Röd, Silver	1	220mm	2.5	EN 45545-2
64568-109	Fiberförstärkt plast, Aluminium	Röd, Silver	1	160mm	2.5	EN 45545-2
64568-110	Fiberförstärkt plast, Aluminium	Grå, Silver	1	160mm	2.5	EN 45545-2
64568-112	Fiberförstärkt plast, Aluminium	Grå, Silver	1	220mm	2.5	EN 45545-2
24568-356	Fiberförstärkt plast	Röd	10	160mm	2	EN 45545-2
24568-357	Fiberförstärkt plast	Röd	10	70mm	2	EN 45545-2
24568-358	Fiberförstärkt plast	Grå	10	160mm	2	EN 45545-2
24568-360	Fiberförstärkt plast	Grå	10	70mm	2	EN 45545-2
24568-331	Fiberförstärkt plast, Aluminium	Röd, Silver	10	280mm	2.5	EN 45545-2
24568-332	Fiberförstärkt plast, Aluminium	Röd, Silver	10	340mm	2.5	EN 45545-2

Katalognummer	Material	Färg	Antal i förpackningen	Kortdjup	Spårbredd	Uppfyller
24568-341	Fiberförstärkt plast, Aluminium	Grå, Silver	10	280mm	2.5	EN 45545-2
24568-342	Fiberförstärkt plast, Aluminium	Grå, Silver	10	340mm	2.5	EN 45545-2

Table 2/2

Katalognummer	Yta	Snabbleverans
64568-089		Nej
64568-090		Nej
64568-085		Nej
64568-086		Nej
64568-091		Nej
64568-092		Nej
64568-111		Nej
64568-109		Nej
64568-110		Nej
64568-112		Nej
24568-356		Nej
24568-357		Nej
24568-358		Nej
24568-360		Nej

Katalognummer	Yta	Snabbleverans
24568-331	Anodiserad	Nej
24568-332	Anodiserad	Nej
24568-341	Anodiserad	Nej
24568-342		Nej

YTTERLIGARE PRODUKTINFORMATION

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE