


Guide Rail Multi Piece, Mid-Piece Aluminium/Plastic Extrusion

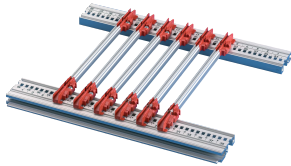

Guide rail mid-piece for individual multi-piece guide rails out of plastic or Aluminum extrusion. Suitable for Standard, Accessory, 4.4" PCB types and end pieces with coding.

CERTIFIERINGAR



DESIGN

Middle profile for mounting guide rails for 2 mm groove width

2 plastic end pieces are required; these are pushed on to both ends of the middle profile

Guide rails can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Storage temperature: from -40 °C ... 130 °C

SPECIFIKATIONER

Produktfamilj:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
Produkttyp:	Styrskena
Typ:	Mittsektion

Table 1/2

Katalognummer	Material	Färg	Antal i förpackningen	Kortdjup	Spårbredd	Färgkod
34560-891	Aluminium	Silver	1	160mm	2	

Katalognummer	Material	Färg	Antal i förpackningen	Kortdjup	Spårbredd	Färgkod
34560-892	Aluminium	Silver	1	220mm	2	
34560-893	Aluminium	Silver	1	280mm	2	
34560-900	Aluminium	Silver	1	1000mm	2	
34564-891	PVC	Grå	1	160mm	2	RAL 7035
34564-892	PVC	Grå	1	220mm	2	RAL 7035
34564-893	PVC	Grå	1	280mm	2	RAL 7035
34564-900	PVC	Grå	1	1000mm	2	RAL 7035

Table 2/2

Katalognummer	Yta	Fungerar med	Snabbleverans
34560-891	Anodiserad	Underrack, Lådor, Chassi	Nej
34560-892	Anodiserad	Underrack, Lådor, Chassi	Nej
34560-893	Anodiserad	Underrack, Lådor, Chassi	Nej
34560-900	Anodiserad	Underrack, Lådor, Chassi	Nej
34564-891		Underrack, Lådor, Chassi	Nej
34564-892		Underrack, Lådor, Chassi	Nej
34564-893		Underrack, Lådor, Chassi	Nej
34564-900		Underrack, Lådor, Chassi	Nej

YTTERLIGARE PRODUKTINFORMATION

Delivery may be in Standard Pack Quantity (SPQ). Pricing is per individual item.

One guide rail consists of 1 pair of head pieces and 1 profile piece.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE