


# PropacPRO Rear Hood

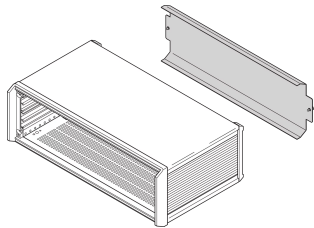

The rear hood can be assembled onto a rear panel of a PropacPRO case. The rear hood enables an additional space between the rear panel and the hood to provide space to store a cable. Can be unscrewed from the rear side.

## CERTIFIERINGAR



## DESIGN

Al material 1.0 mm, RAL 9006

The fixing is done with two knurled screws

## SPECIFIKATIONER

|                       |                |
|-----------------------|----------------|
| <b>Material:</b>      | Aluminium      |
| <b>Fungerar med:</b>  | Lådor          |
| <b>Produkttyp:</b>    | Hölje          |
| <b>Yta:</b>           | Pulverlackerad |
| <b>Produktfamilj:</b> | PropacPRO      |
| <b>Typ:</b>           | Bakre huv      |

Table 1/1

| Katalognummer | Rackhöjd | Rackbredd | Antal i förpackningen | Snabbleverans |
|---------------|----------|-----------|-----------------------|---------------|
| 24576-086     | 3U       | 42HP      | 1                     | Nej           |
| 24576-088     | 3U       | 84HP      | 1                     | Nej           |
| 24576-092     | 4U       | 84HP      | 1                     | Nej           |

| Katalognummer | Rackhöjd | Rackbredd | Antal i förpackningen | Snabbleverans |
|---------------|----------|-----------|-----------------------|---------------|
| 24576-087     | 3U       | 63HP      | 1                     | Nej           |
| 24576-091     | 4U       | 63HP      | 1                     | Nej           |

## YTTERLIGARE PRODUKTINFORMATION

To install the rear hood, feet must be fitted to the rear panel; please order separately.

## VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på [www.nvent.com](http://www.nvent.com) och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vårt starka utbud av varumärken:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**