


RatiopacPRO EMC Front Panel, Slotted, Shielded

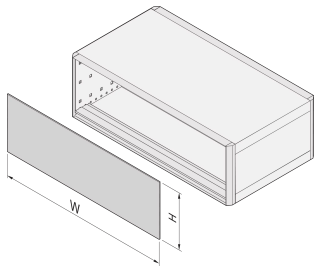

The EMC front panel can be inserted in special horizontal rails with an elevation. No screws are needed for the fixing. The design enable a users to use a front foil.

CERTIFIERINGAR



DESIGN

Fixing does not require screws

Special horizontal rails cover the edges of the front panel (top and bottom) and prevent bowing of the front panel

SPECIFIKATIONER

Material:	Aluminium
Yta:	Anodiserad; Passiverad
Tillbehörstyp:	Frontpanel
Produkttyp:	Frontpanel

Table 1/2

Katalognummer	Rackhöjd	Rackbredd	Antal i förpackningen	Främre finish	Bakre finish	Behandlade kanter
24572-603	3U	28HP	1	Anodiserad	Ledande	Nej
24572-604	3U	42HP	1	Anodiserad	Ledande	Nej

Katalognummer	Rackhöjd	Rackbredd	Antal i förpackningen	Främre finish	Bakre finish	Behandlade kanter
24572-605	3U	63HP	1	Anodiserad	Ledande	Nej
24572-606	3U	84HP	1	Anodiserad	Ledande	Nej
24572-607	4U	28HP	1	Anodiserad	Ledande	Nej
24572-608	4U	42HP	1	Anodiserad	Ledande	Nej
24572-609	4U	63HP	1	Anodiserad	Ledande	Nej
24572-610	4U	84HP	1	Anodiserad	Ledande	Nej
24572-599	2U	28HP	1	Anodiserad	Ledande	Nej
24572-600	2U	42HP	1	Anodiserad	Ledande	Nej
24572-601	2U	63HP	1	Anodiserad	Ledande	Nej
24572-602	2U	84HP	1	Anodiserad	Ledande	Nej

Table 2/2

Katalognummer	Djup	Höjd	Bredd	Snabbleverans
24572-603	2.5mm	128.4mm	141.9mm	Nej
24572-604	2.5mm	128.4mm	213.2mm	Nej
24572-605	2.5mm	128.4mm	319.7mm	Nej
24572-606	2.5mm	128.4mm	426.4mm	Nej
24572-607	2.5mm	172.9mm	141.9mm	Nej
24572-608	2.5mm	172.9mm	213.2mm	Nej
24572-609	2.5mm	172.9mm	319.7mm	Nej

Katalognummer	Djup	Höjd	Bredd	Snabbleverans
24572-610	2.5mm	172.9mm	426.4mm	Nej
24572-599	2.5mm	84mm	141.9mm	Nej
24572-600	2.5mm	84mm	213.2mm	Nej
24572-601	2.5mm	84mm	319.7mm	Nej
24572-602	2.5mm	84mm	426.4mm	Nej

YTTERLIGARE PRODUKTINFORMATION

To obtain a shielded case, all EMC sealings must be fitted (front panel/rear panel - side panel; side panel - cover plate; front panel/rear panel - horizontal rail; horizontal rail - horizontal rail).

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE