


Rear Panel for RatiopacPRO/PropacPRO, Perforated, Unshielded

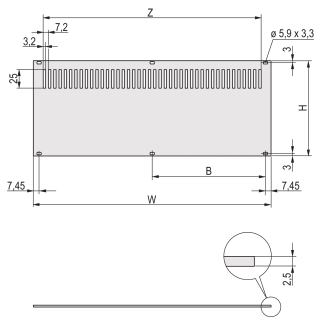

The perforated rear panel, Al, 2.5 mm is unshielded. The rear side is conductive.

CERTIFIERINGAR



DESIGN

Rear panel, Al, 2.5 mm, front: anodized, rear: conductive; unshielded

Enables mounting on horizontal rails

For Mounting on Horizontal Rails

SPECIFIKATIONER

Material:	Aluminium
Yta:	Anodiserad; Passiverad
Fungerar med:	Lådor
Produktfamilj:	RatiopacPRO; RatiopacPRO AIR
Typ:	Bakre panel
Produkttyp:	Sidopanel

Table 1/1

Table 1/1						
Katalognummer	Rackhöjd	Rackbredd	Antal i förpackningen	Höjd	Bredd	Snabbleverans

30849-014	2U	42HP	1	67.9mm	213mm	Nej
30849-016	2U	84HP	1	67.9mm	426.4mm	Nej
30849-008	3U	28HP	1	112.35mm	141.9mm	Nej
30849-021	3U	42HP	1	112.35mm	213mm	Nej
30849-022	3U	63HP	1	112.35mm	319.7mm	Nej
30849-023	3U	84HP	1	112.35mm	426.4mm	Nej
30849-028	4U	42HP	1	156.8mm	213mm	Nej
30849-029	4U	63HP	1	156.8mm	319.7mm	Nej
30849-030	4U	84HP	1	156.8mm	426.4mm	Nej
30849-037	6U	84HP	1	245.7mm	426.4mm	Nej
30849-036	6U	63HP	1	245.7mm	319.7mm	Nej
30849-015	2U	63HP	1	67.9mm	319.7mm	Nej
30849-009	4U	28HP	1	156.8mm	141.9mm	Nej
30849-010	6U	28HP	1	245.7mm	141.9mm	Nej
30849-035	6U	42HP	1	245.7mm	213mm	Nej
30849-007	2U	28HP	1	67.9mm	141.9mm	Nej
30849-011	5U	28HP	1	220mm	215mm	Nej
30849-171	5U	42HP	1	220mm	215mm	Nej
30849-172	5U	63HP	1	220mm	215mm	Nej

30849-173		84HP	1	220mm	215mm	Nej
-----------	--	------	---	-------	-------	-----

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE