


U-profile Front Panel, Shieldable, D-Sub Cutouts

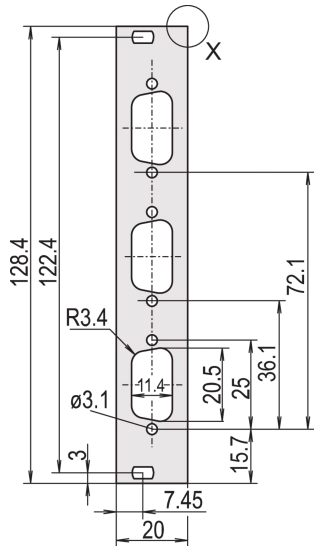

U-profile front panel with cutout for D-Sub connectors.
Shieldable for textile EMC gasket.

CERTIFIERINGAR



DESIGN

U-profile, front panel, Al, 2.5 mm, front anodized, rear conductive

For EMC textile gasket

SPECIFIKATIONER

Djup (D):	2.5mm
Rackhöjd:	3U
Rackbredd:	4HP
Material:	Aluminium
Yta:	Anodiserad; Passiverad
Tillbehörstyp:	Frontpanel
Produkttyp:	Frontpanel
Typ:	Frontpanel utan handtag

EMC-skydd: Nej (kan eftermonteras)

Table 1/2

Katalognummer	Antal i förpackningen	Montage	EMC-packningstyp	Främre finish	Bakre finish	Antal stift
30849-749	1	Skrivas på front	Textil	Anodiserad	Ledande	(1) 9
30849-750	1	Skrivas på front	Textil	Anodiserad	Ledande	(2) 9
30849-751	1	Skrivas på front	Textil	Anodiserad	Ledande	(3) 9
30849-752	1	Skrivas på front	Textil	Anodiserad	Ledande	(1) 15
30849-753	1	Skrivas på front	Textil	Anodiserad	Ledande	(2) 15
30849-754	1	Skrivas på front	Textil	Anodiserad	Ledande	(1) 25
30849-755	1	Skrivas på front	Textil	Anodiserad	Ledande	(2) 25

Table 2/2

Katalognummer	Behandlade kanter	Uppfyller	Höjd (H)	Bredd (W)	Snabbleverans
30849-749	Nej	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej
30849-750	Nej	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej
30849-751	Nej	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej
30849-752	Nej	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej
30849-753	Nej	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej
30849-754	Nej	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej
30849-755	Nej	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	Nej

YTTERLIGARE PRODUKTINFORMATION


Please order fixing material (sleeves, collar screws) separately.


Delivery is in standard pack multiples. Pricing is per individual item.

Please order textile EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

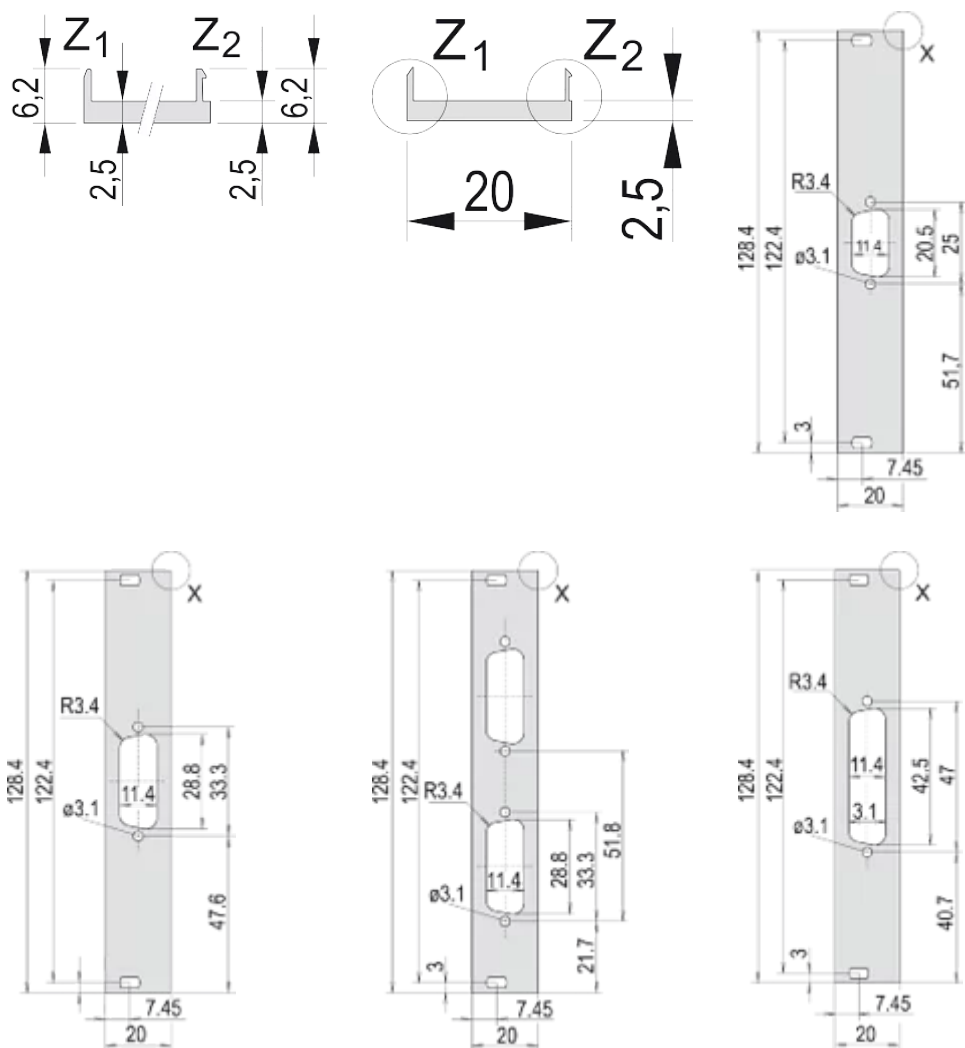

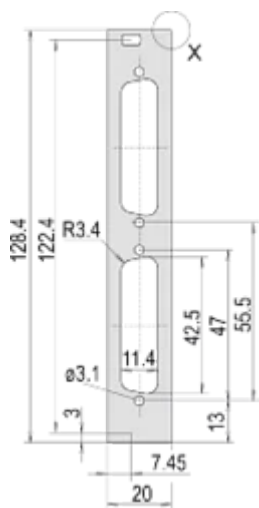

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE