


Varistar CP Double Glazed Door, IP 20, 3-Point Locking

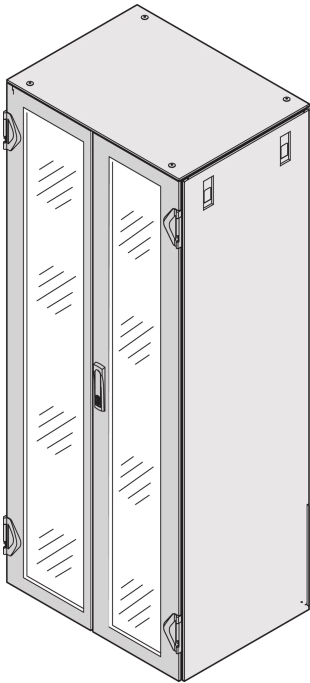

DESIGN

Lever handle with key insert (2 keys)

Frame, St, 1.5 mm

Opening angle 180°

Security glass, 6 mm

Can be retrofitted with DIN profile half cylinder

Ingress protection class IP 20

Standard fitting, lock on right-hand door

SPECIFIKATIONER

Låstyp:	3-punktslås
Produkttyp:	Skåpdörr
Kapslingsklass:	IP20
Material:	Stål

Table 1/2

Katalognummer	Rackhöjd	Höjd	Bredd	Antal i förpackningen	Färg	Färgkod
21630-686	24U	1200mm	600mm	1	Svartgrå	RAL 7021
21630-687	24U	1200mm	800mm	1	Svartgrå	RAL 7021
21630-688	29U	1400mm	600mm	1	Svartgrå	RAL 7021
21630-689	29U	1400mm	800mm	1	Svartgrå	RAL 7021
21630-690	33U	1600mm	600mm	1	Svartgrå	RAL 7021
21630-691	33U	1600mm	800mm	1	Svartgrå	RAL 7021
21630-692	38U	1800mm	600mm	1	Svartgrå	RAL 7021
21630-693	38U	1800mm	800mm	1	Svartgrå	RAL 7021
21630-694	42U	2000mm	600mm	1	Svartgrå	RAL 7021
21630-695	42U	2000mm	800mm	1	Svartgrå	RAL 7021
21630-696	47U	2200mm	600mm	1	Svartgrå	RAL 7021
21630-697	47U	2200mm	800mm	1	Svartgrå	RAL 7021

Table 2/2

Katalognummer	Yta	Typ	Snabbleverans
21630-686	Pulverlackerad	Dubbel glasdörr	Nej
21630-687	Pulverlackerad	Dubbel glasdörr	Nej
21630-688	Pulverlackerad	Dubbel glasdörr	Nej
21630-689	Pulverlackerad	Dubbel glasdörr	Nej

Katalognummer	Yta	Typ	Snabbleverans
21630-690	Pulverlackerad	Dubbel glasdörr	Nej
21630-691	Pulverlackerad	Dubbel glasdörr	Nej
21630-692	Pulverlackerad	Dubbel glasdörr	Nej
21630-693	Pulverlackerad	Dubbel glasdörr	Nej
21630-694	Pulverlackerad	Dubbel glasdörr	Nej
21630-695	Pulverlackerad	Dubbel glasdörr	Nej
21630-696	Pulverlackerad	Dubbel glasdörr	Nej
21630-697	Pulverlackerad	Dubbel glasdörr	Nej

YTTERLIGARE PRODUKTINFORMATION

Perforated Varistar CP glass double door with 3-point locking for applications with IP 20 protection.

24U - 33U IP20 doors have 2 hinges, 38U - 52U IP20 doors have 3 hinges to ensure robust IP20 closing structures for taller cabinets

Please order lever handle 24630003 and the DIN lock separately if you want to replace the 1333 DIN lock lever handle.

Please purchase the grounding kit separately.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE