


Varistar CP Seismic Base Plate, Multi-Piece

Multi piece base plate is assembled from inside.

Please order grounding, cover plate, brush strip or filter mat separately.

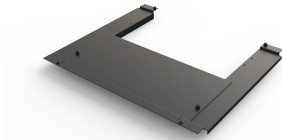

DESIGN

To cover the base opening

The multi-piece base plate is open at the rear (opening to rear 200 mm deep, no rear opening with 300 mm cabinet depth)

SPECIFIKATIONER

Produkttyp: Skåp/rackbas

Material: Stål

Table 1/2

Katalognummer	Bredd	Djup	Antal i förpackningen	Färg	Färgkod	Uppfyller
20630-293	600mm	600mm	1	Svartgrå	RAL 7021	IEC 61587-1, IEC 61587-2
20630-294	600mm	800mm	1	Svartgrå	RAL 7021	IEC 61587-1, IEC 61587-2
20630-295	600mm	1000mm	1	Svartgrå	RAL 7021	IEC 61587-1, IEC 61587-2
20630-296	600mm	1200mm	1	Svartgrå	RAL 7021	IEC 61587-1, IEC 61587-2
20630-297	800mm	600mm	1	Svartgrå	RAL 7021	IEC 61587-1, IEC 61587-2
20630-298	800mm	800mm	1	Svartgrå	RAL 7021	IEC 61587-1, IEC 61587-2

Katalognummer	Bredd	Djup	Antal i förpackningen	Färg	Färgkod	Uppfyller
20630-299	800mm	1000mm	1	Svartgrå	RAL 7021	IEC 61587-1, IEC 61587-2
20630-300	800mm	1200mm	1	Svartgrå	RAL 7021	IEC 61587-1, IEC 61587-2

Table 2/2

Katalognummer	Yta	Typ	Fungerar med	Snabbleverans
20630-293	Pulverlackerad	Basplatta, standard	Varistar CP	Nej
20630-294	Pulverlackerad	Basplatta, standard	Varistar CP	Nej
20630-295	Pulverlackerad	Basplatta, standard	Varistar CP	Nej
20630-296	Pulverlackerad	Basplatta, standard	Varistar CP	Nej
20630-297	Pulverlackerad	Basplatta, standard	Varistar CP	Nej
20630-298	Pulverlackerad	Basplatta, standard	Varistar CP	Nej
20630-299	Pulverlackerad	Basplatta, standard	Varistar CP	Nej
20630-300	Pulverlackerad	Basplatta, standard	Varistar CP	Nej

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE