

Branch Line Restraint Structure Attachment to Wood/Concrete



认证



功能

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to wood or concrete where cracked concrete approval is not needed

技术参数

完成: 电镀锌

材料: 钢

Table 1/2


物料号	订货号	杆尺寸 (RS)	高度 (H)	长度 (L)	宽度 (W)	螺钉长度 (L)
CSBBRS2MEG	402240	10, 12	28.2 mm	40.4mm	26.9 mm	44.5mm
CSBBRS2EG		0.375, 0.5	28.2 mm	40.4mm	26.9 mm	44.5mm

Table 2/2		
物料号	订货号	钻头直径
CSBBRS2MEG	402240	5mm
CSBBRS2EG		5mm

其他产品详情

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

图

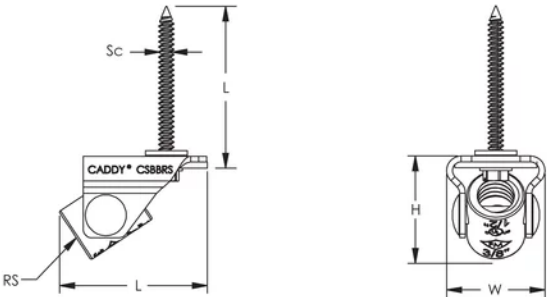

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

