

HD Heavy Duty Pipe Clamp



认证



功能

Fillet welded connector nut has flats to accommodate spanners

Easy open flange for pipe sizes less than 4"

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

技术参数

颜色: 黑色

完成: 电镀锌

温度: -50 to 110 °C

Table 1/3

物料号	订货号	材料	外径 (OD)	NB/DN	杆尺寸 (RS)	宽度 (W)
-----	-----	----	---------	-------	----------	--------

HDI018	577033	钢, EPDM-SBR Rubber	14 - 18 mm	10	M8, M10	30 mm
HDI023	577034	钢, EPDM-SBR Rubber	19 - 23 mm	15	M8, M10	30 mm
HDI028	577035	钢, EPDM-SBR Rubber	24 - 28 mm	20	M8, M10	30 mm
HDI033	577036	钢, EPDM-SBR Rubber	29 - 33 mm	25	M8, M10	30 mm
HDI037	577037	钢, EPDM-SBR Rubber	33 - 37 mm		M8, M10	30 mm
HDI045	577038	钢, EPDM-SBR Rubber	40 - 45 mm	32	M8, M10	30 mm
HDI052	577039	钢, EPDM-SBR Rubber	47 - 52 mm	40	M8, M10	30 mm
HDI058	577040	钢, EPDM-SBR Rubber	53 - 58 mm		M8, M10	30 mm
HDI065	577041	钢, EPDM-SBR Rubber	60 - 65 mm	50	M8, M10	30 mm
HDI072	577042	钢, EPDM-SBR Rubber	67 - 72 mm		M10, M12	30 mm
HDI078	577043	钢, EPDM-SBR Rubber	73 - 78 mm	65	M10, M12	30 mm
HDI085	577044	钢, EPDM-SBR Rubber	79 - 85 mm		M10, M12	30 mm
HDI093	577045	钢, EPDM-SBR Rubber	88 - 93 mm	80	M10, M12	30 mm
HDI099	577046	钢, EPDM-SBR Rubber	94 - 99 mm		M10, M12	30 mm
HDI106	577047	钢, EPDM-SBR Rubber	100 - 106 mm		M10, M12	30 mm
HDI116	577048	钢, EPDM-SBR Rubber	108 - 116 mm	100	M10, M12	30 mm
HDI123	577049	钢, EPDM-SBR Rubber	117 - 123 mm		M10, M12	30 mm

HDI129	577050	钢, EPDM-SBR Rubber	124 - 129 mm		M10, M12	40 mm
HDI137	577051	钢, EPDM-SBR Rubber	131 - 137 mm		M12, M16	40 mm
HDI145	577052	钢, EPDM-SBR Rubber	138 - 145 mm	125	M12, M16	40 mm
HDI154	577053	钢, EPDM-SBR Rubber	148 - 154 mm		M12, M16	40 mm
HDI162	577054	钢, EPDM-SBR Rubber	156 - 162 mm		M12, M16	40 mm
HDI171	577055	钢, EPDM-SBR Rubber	165 - 171 mm	150	M12, M16	40 mm
HDI183	577056	钢, EPDM-SBR Rubber	177 - 183 mm		M12, M16	40 mm
HDI194	577057	钢, EPDM-SBR Rubber	188 - 194 mm		M12, M16	40 mm
HDI203	577058	钢, EPDM-SBR Rubber	196 - 203 mm		M12, M16	40 mm
HDI214	577059	钢, EPDM-SBR Rubber	205 - 214 mm		M12, M16	40 mm
HDI225	577061	钢, EPDM-SBR Rubber	219 - 225 mm	200	M16, M20	40 mm
HDI236	577063	钢, EPDM-SBR Rubber	226 - 236 mm		M16, M20	40 mm
HDI250	577064	钢, EPDM-SBR Rubber	244 - 250 mm		M16, M20	40 mm
HDI261	577065	钢, EPDM-SBR Rubber	251 - 261 mm		M16, M20	40 mm
HDI273	577066	钢, EPDM-SBR Rubber	265 - 273 mm	250	M16, M20	40 mm
HDI316	577067	钢, EPDM-SBR Rubber	305 - 316 mm		M16, M20	40 mm

Table 2/3

物料号	订货号	厚度 (T)	螺钉直径 (Sc)	螺钉直径 (公制) (Sc)	螺钉长度 (L)	静态负载
-----	-----	--------	-----------	-------------------	----------	------

HDI018	577033	2.5 mm	6 mm	M6	30mm	2000N
HDI023	577034	2.5 mm	6 mm	M6	30mm	2000N
HDI028	577035	2.5 mm	6 mm	M6	30mm	2000N
HDI033	577036	2.5 mm	6 mm	M6	30mm	2000N
HDI037	577037	2.5 mm	6 mm	M6	30mm	2000N
HDI045	577038	2.5 mm	6 mm	M6	30mm	2000N
HDI052	577039	2.5 mm	6 mm	M6	30mm	2000N
HDI058	577040	2.5 mm	6 mm	M6	30mm	2000N
HDI065	577041	2.5 mm	8 mm	M8	40mm	2000N
HDI072	577042	3 mm	8 mm	M8	40mm	2000N
HDI078	577043	3 mm	8 mm	M8	40mm	3500N
HDI085	577044	3 mm	8 mm	M8	40mm	3500N
HDI093	577045	3 mm	8 mm	M8	40mm	3500N
HDI099	577046	3 mm	8 mm	M8	40mm	3500N
HDI106	577047	3 mm	8 mm	M8	40mm	3500N
HDI116	577048	3 mm	8 mm	M8	40mm	3500N
HDI123	577049	3 mm	8 mm	M8	40mm	3500N

HDI129	577050	4 mm	8 mm	M8	40mm	3500N
HDI137	577051	4 mm	10 mm	M10	40mm	3500N
HDI145	577052	4 mm	10 mm	M10	40mm	5000N
HDI154	577053	4 mm	10 mm	M10	40mm	5000N
HDI162	577054	4 mm	10 mm	M10	40mm	5000N
HDI171	577055	4 mm	10 mm	M10	40mm	5000N
HDI183	577056	4 mm	10 mm	M10	40mm	5000N
HDI194	577057	4 mm	10 mm	M10	40mm	5000N
HDI203	577058	4 mm	10 mm	M10	40mm	5000N
HDI214	577059	4 mm	10 mm	M10	40mm	5000N
HDI225	577061	4 mm	12 mm	M12	40mm	10000N
HDI236	577063	4 mm	12 mm	M12	40mm	10000N
HDI250	577064	4 mm	12 mm	M12	40mm	10000N
HDI261	577065	4 mm	12 mm	M12	40mm	10000N
HDI273	577066	4 mm	12 mm	M12	40mm	10000N
HDI316	577067	4 mm	12 mm	M12	40mm	10000N

Table 3/3

物料号	订货号	认证
-----	-----	----


HDI018	577033	ITB
HDI023	577034	ITB
HDI028	577035	ITB
HDI033	577036	ITB
HDI037	577037	ITB
HDI045	577038	ITB
HDI052	577039	ITB
HDI058	577040	ITB
HDI065	577041	ITB
HDI072	577042	
HDI078	577043	ITB
HDI085	577044	
HDI093	577045	ITB
HDI099	577046	
HDI106	577047	ITB
HDI116	577048	ITB
HDI123	577049	ITB

HDI129	577050	ITB
HDI137	577051	ITB
HDI145	577052	ITB
HDI154	577053	ITB
HDI162	577054	ITB
HDI171	577055	ITB
HDI183	577056	ITB
HDI194	577057	
HDI203	577058	ITB
HDI214	577059	ITB
HDI225	577061	ITB
HDI236	577063	
HDI250	577064	ITB
HDI261	577065	ITB
HDI273	577066	ITB
HDI316	577067	ITB

其他产品详情

Lining is EPDM rubber.

图

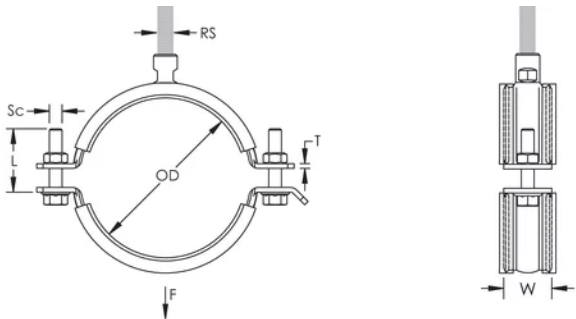

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

