

HD NI Heavy Duty Pipe Clamp, Fire/Sprinkler



认证



功能

Fillet welded connector nut has flats to accommodate spanners

技术参数

材料: 钢

Table 1/3

物料号	订货号	包含螺母	完成	外径 (OD)	NB/DN	杆尺寸 (RS)
HDN024	577002	是	电镀锌	20 - 24 mm	15	M8, M10
HDN024HD	575002	是	热浸镀锌	20 - 24 mm	15	M8, M10
HDN030	577003	是	电镀锌	25 - 30 mm	20	M8, M10

物料号	订货号	包含螺母	完成	外径 (OD)	NB/DN	杆尺寸 (RS)
HDN035	577004	是	电镀锌	31 - 35 mm	25	M8, M10
HDN035HD	575004	是	热浸镀锌	31 - 35 mm	25	M8, M10
HDN045HD	575006	是	热浸镀锌	40 - 45 mm	32	M8, M10
HDN059	577008	是	电镀锌	54 - 59 mm		M8, M10
HDN059HD	575008	是	热浸镀锌	54 - 59 mm		M8, M10
HDN065	577009	是	电镀锌	60 - 65 mm	50	M8, M10
HDN081	577011	是	电镀锌	76 - 81 mm	65	M10, M12
HDN085	577012	是	电镀锌	82 - 85 mm		M10, M12
HDN094HD	575013	是	热浸镀锌	88 - 94 mm	80	M10, M12
HDN102	577014	是	电镀锌	95 - 102 mm		M10, M12
HDN108	577015	是	电镀锌	102 - 108 mm		M10, M12
HDN116	577016	是	电镀锌	110 - 116 mm	100	M10, M12
HDN124	577017	是	电镀锌	117 - 124 mm		M10, M12
HDN129HD	575018	是	热浸镀锌	124 - 129 mm		M10, M12
HDN140	577019	是	电镀锌	133 - 140 mm		M10, M12
HDN155	577021	是	电镀锌	149 - 155 mm		M12, M16
HDN173	577023	是	电镀锌	167 - 173 mm	150	M12, M16

物料号	订货号	包含螺母	完成	外径 (OD)	NB/DN	杆尺寸 (RS)
HDN173HD	575023	是	热浸镀锌	167 - 173 mm	150	M12, M16
HDN182	577024	是	电镀锌	176 - 182 mm		M12, M16
HDN205	577026	是	电镀锌	199 - 205 mm		M12, M16
HDN216	577027	是	电镀锌	207 - 216 mm		M12, M16
HDN226	577028	是	电镀锌	219 - 226 mm	200	M12, M16
HDN226HD	575028	是	热浸镀锌	219 - 226 mm	200	M12, M16
HDN236	577029	是	电镀锌	227 - 236 mm		M16, M20
HDN316	577068	是	电镀锌	305 - 316 mm		M16, M20

Table 2/3						
物料号	订货号	宽度 (W)	厚度 (T)	螺钉直径 (Sc)	螺钉直径 (公制) (Sc)	螺钉长度 (L)
HDN024	577002	30 mm	2.5 mm	6 mm	M6	30mm
HDN024HD	575002	30 mm	2.5 mm	6 mm	M6	30mm
HDN030	577003	30 mm	2.5 mm	6 mm	M6	30mm
HDN035	577004	30 mm	2.5 mm	6 mm	M6	30mm
HDN035HD	575004	30 mm	2.5 mm	6 mm	M6	30mm
HDN045HD	575006	30 mm	2.5 mm	6 mm	M6	30mm
HDN059	577008	30 mm	2.5 mm	6 mm	M6	30mm

物料号	订货号	宽度 (W)	厚度 (T)	螺钉直径 (Sc)	螺钉直径 (公制) (Sc)	螺钉长度 (L)
HDN059HD	575008	30 mm	2.5 mm	6 mm	M6	30mm
HDN065	577009	30 mm	2.5 mm	6 mm	M6	30mm
HDN081	577011	30 mm	3 mm	8 mm	M8	40mm
HDN085	577012	30 mm	3 mm	8 mm	M8	40mm
HDN094HD	575013	30 mm	3 mm	8 mm	M8	40mm
HDN102	577014	30 mm	3 mm	8 mm	M8	40mm
HDN108	577015	30 mm	3 mm	8 mm	M8	40mm
HDN116	577016	30 mm	3 mm	8 mm	M8	40mm
HDN124	577017	30 mm	3 mm	8 mm	M8	40mm
HDN129HD	575018	30 mm	3 mm	8 mm	M8	40mm
HDN140	577019	40 mm	4 mm	8 mm	M8	40mm
HDN155	577021	40 mm	4 mm	10 mm	M10	40mm
HDN173	577023	40 mm	4 mm	10 mm	M10	40mm
HDN173HD	575023	40 mm	4 mm	10 mm	M10	40mm
HDN182	577024	40 mm	4 mm	10 mm	M10	40mm
HDN205	577026	40 mm	4 mm	10 mm	M10	40mm

物料号	订货号	宽度 (W)	厚度 (T)	螺钉直径 (Sc)	螺钉直径 (公制) (Sc)	螺钉长度 (L)
HDN216	577027	40 mm	4 mm	10 mm	M10	40mm
HDN226	577028	40 mm	4 mm	10 mm	M10	40mm
HDN226HD	575028	40 mm	4 mm	10 mm	M10	40mm
HDN236	577029	40 mm	4 mm	12 mm	M12	40mm
HDN316	577068	40 mm	4 mm	12 mm	M12	40mm


Table 3/3

物料号	订货号	静态负载	认证
HDN024	577002	2000N	ITB
HDN024HD	575002	2000N	
HDN030	577003	2000N	ITB, FM Approved, Pipe Hanger Components, VdS G4090030
HDN035	577004	2000N	FM Approved, Pipe Hanger Components, VdS G4090030, ITB
HDN035HD	575004	2000N	FM Approved, Pipe Hanger Components, VdS G4090030
HDN045HD	575006	2000N	FM Approved, Pipe Hanger Components, VdS G4090030
HDN059	577008	2000N	VdS G4090030, ITB
HDN059HD	575008	2000N	VdS G4090030

物料号	订货号	静态负载	认证
HDN065	577009	2000N	FM Approved, Pipe Hanger Components, VdS G4090030, ITB
HDN081	577011	3500N	FM Approved, Pipe Hanger Components, VdS G4090030, ITB, AON Fire Protection, BB019, pipe hangers
HDN085	577012	3500N	VdS G4090030, AON Fire Protection, BB019, pipe hangers
HDN094HD	575013	3500N	FM Approved, Pipe Hanger Components, VdS G4090030
HDN102	577014	3500N	VdS G4090030, ITB, AON Fire Protection, BB019, pipe hangers
HDN108	577015	3500N	VdS G4090030, ITB, AON Fire Protection, BB019, pipe hangers
HDN116	577016	3500N	FM Approved, Pipe Hanger Components, VdS G4090030, ITB, AON Fire Protection, BB019, pipe hangers
HDN124	577017	5000N	VdS G4090030, AON Fire Protection, BB019, pipe hangers
HDN129HD	575018	5000N	VdS G4090030
HDN140	577019	5000N	VdS G4090030, ITB, AON Fire Protection, BB019, pipe hangers
HDN155	577021	5000N	VdS G4090030, ITB, AON Fire Protection, BB019, pipe hangers

物料号	订货号	静态负载	认证
HDN173	577023	5000N	FM Approved, Pipe Hanger Components, VdS G4090030, ITB, AON Fire Protection, BB019, pipe hangers
HDN173HD	575023	5000N	FM Approved, Pipe Hanger Components, VdS G4090030
HDN182	577024	8500N	ITB
HDN205	577026	8500N	ITB
HDN216	577027	8500N	ITB
HDN226	577028	8500N	ITB, VdS G4090030
HDN226HD	575028	8500N	VdS G4090030
HDN236	577029	10000N	ITB
HDN316	577068	10000N	ITB

图

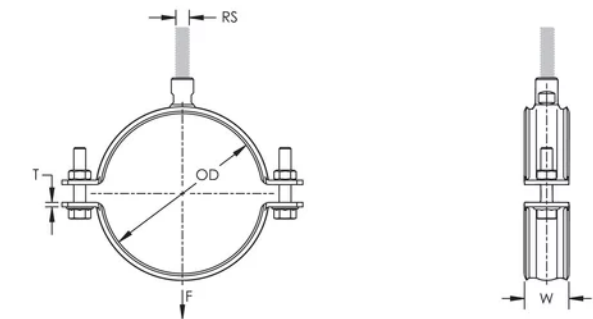

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

