

MACRO V Duct Clamp



功能

Quick locking system for outer diameters up to 400 mm

Achieved noise reduction up to 16 dB(A) in controlled testing

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

技术参数

温度: -50 to 110 °C

完成: 电镀锌


材料: 钢;EPDM-SBR 橡胶

Table 1/2

物料号	订货号	外径 (OD)	杆尺寸 1 (RS1)	杆尺寸 2 (RS2)	宽度 (W)	厚度 (T)
MVI0150EG	582420	150 mm	8	10	23 mm	1.5 mm
MVI0180EG	582440	180 mm	8	10	23 mm	1.5 mm
MVI0100EG	582360	100 mm	8	10	23 mm	1.5 mm
MVI0280EG	582490	280 mm	8	10	23 mm	2 mm

物料号	订货号	外径 (OD)	杆尺寸 1 (RS1)	杆尺寸 2 (RS2)	宽度 (W)	厚度 (T)
MVI0224EG	582470	224 mm	8	10	23 mm	2 mm
MVI0355EG	582530	355 mm	8	10	23 mm	2 mm
MVI0300EG	582500	300 mm	8	10	23 mm	2 mm
MVI0250EG	582480	250 mm	8	10	23 mm	2 mm

Table 2/2				
物料号	订货号	螺钉直径 (Sc)	螺钉长度 (L)	静态负载
MVI0150EG	582420	6	40mm	750N
MVI0180EG	582440	6	40mm	750N
MVI0100EG	582360	6	30mm	750N
MVI0280EG	582490	6	40mm	750N
MVI0224EG	582470	6	40mm	750N
MVI0355EG	582530	6	40mm	750N
MVI0300EG	582500	6	40mm	750N
MVI0250EG	582480	6	40mm	750N

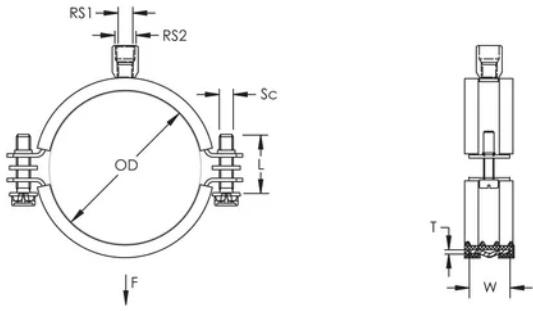

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

