

Standard Universal Sway Brace



认证



Korea Fire Institute

功能

Use for both lateral and longitudinal sway brace applications

Snap-off bolt head helps enable easy installation and inspection of seismic sway braces

Works with 1" through 2" brace pipes to reduce inventory

Slotted design grabs service pipe for added gripping strength

Meets NFPA®-13 requirements for seismic sway bracing

Meets CEN/TS 17551:2021 requirements for Seismic Sway Bracing

技术参数

完成: 电镀锌

Table 1/1

物料号	订货号	材料	NB/DN	A	B	认证
CSBSTU0100E G	404385	钢, Cast Iron	25	174.6 mm	25 mm	UL, FM Approved, Seismic, AON Fire Protection, Rigid Seismic, OSHDP, cUL
CSBSTU0125E G	404386	钢, Cast Iron	32	187.4 mm	25.4 mm	cUL, AON Fire Protection, Rigid Seismic, UL, FM Approved, Seismic, OSHDP
CSBSTU0150E G	404387	钢, Cast Iron	40	196.9 mm	25.4 mm	OSHDP, AON Fire Protection, Rigid Seismic, cUL, UL, FM Approved, Seismic
CSBSTU0200E G	404388	钢, Cast Iron	50	206.4 mm	30.2 mm	UL, FM Approved, Seismic, AON Fire Protection, Rigid Seismic, OSHDP, cUL
CSBSTU0250E G	404389	钢, Cast Iron	65	225.4 mm	30.2 mm	cUL, AON Fire Protection, Rigid Seismic, UL, FM Approved, Seismic, OSHDP

物料号	订货号	材料	NB/DN	A	B	认证
CSBSTU0300E G	404390	钢, Cast Iron	80	238.1 mm	30.2 mm	OSHPD, AON Fire Protection, Rigid Seismic, cUL, UL, FM Approved, Seismic
CSBSTU0400E G	404391	钢, Cast Iron	100	269.9 mm	38.1 mm	UL, FM Approved, Seismic, AON Fire Protection, Rigid Seismic, OSHPD, cUL
CSBSTU0500E G	404392	钢, Cast Iron	125	308 mm	38.1 mm	cUL, AON Fire Protection, Rigid Seismic, UL, FM Approved, Seismic, OSHPD
CSBSTU0600E G	404393	钢, Cast Iron	150	346.1 mm	50.8 mm	OSHPD, AON Fire Protection, Rigid Seismic, cUL, UL, FM Approved, Seismic
CSBSTU0800E G	404394	钢, Cast Iron	200	400.1 mm	50.8 mm	UL, FM Approved, Seismic, AON Fire Protection, Rigid Seismic, Korea Fire Institute, Rigid Seismic, ENG, OSHPD, cUL

物料号	订货号	材料	NB/DN	A	B	认证
CSBSTU1000E G	404395	钢, Cast Iron	250	457.2 mm	50.8 mm	cUL, AON Fire Protection, Rigid Seismic, Korea Fire Institute, Rigid Seismic, ENG, UL, FM Approved, Seismic, OSHPD

其他产品详情

When installed with Schedule 10 and Schedule 40 Service Pipe, use 1" to 2" Schedule 40 NPS as brace member.


When installed with KS D 3507 and KS D 3562 Service Pipe, use 25A to 32A KS D 3562 as brace member.

FM Loads (EN 10255 L, EN10255 M and EN 10255 H Service Pipes)								
Part Number	Horizontal Capacity per Installation Angle from Vertical							
	Lateral				Longitudinal			
	30°- 44°	45°- 59°	60°- 74°	75°- 90°	30°- 44°	45°- 59°	60°- 74°	75°- 90°
CSBSTU0100xx	3825 N	5425 N	6670 N	7430 N	4315 N	3200 N	3825 N	4270 N
CSBSTU0125xx	3825 N	5425 N	6670 N	7430 N	4315 N	3200 N	3825 N	4270 N
CSBSTU0150xx	3825 N	5425 N	6670 N	7430 N	4315 N	3200 N	3825 N	4270 N
CSBSTU0200xx	6805 N	9610 N	11790 N	13165 N	3870 N	3070 N	3690 N	4136 N
CSBSTU0250xx	6805 N	9610 N	11790 N	13165 N	3870 N	3070 N	3690 N	4136 N
CSBSTU0300xx	6805 N	9610 N	11790 N	13165 N	3870 N	3070 N	3690 N	4136 N
CSBSTU0400xx	6985 N	9875 N	12100 N	13480 N	6895 N	6185 N	7475 N	8320 N
CSBSTU0500xx	6985 N	9875 N	12100 N	13480 N	6895 N	6185 N	7475 N	8320 N
CSBSTU0600xx	8805 N	12500 N	15300 N	17080 N	6540 N	5205 N	6270 N	6985 N

FM Loads (4.8 mm wall and EN 10255 H Service Pipes)								
Part Number	Horizontal Capacity per Installation Angle from Vertical							
	Lateral				Longitudinal			
	30°- 44°	45°- 59°	60°- 74°	75°- 90°	30°- 44°	45°- 59°	60°- 74°	75°- 90°
CSBSTU0800xx	9075 N	12855 N	15745 N	17570 N	5340 N	7560 N	9295 N	10365 N
CSBSTU1000xx	9075 N	12855 N	15745 N	17570 N	5340 N	7560 N	9295 N	10365 N

UL Loads (Listed for Restraints)		
Part Number	Lateral	Longitudinal
	Sch 10/Sch 40 Service Pipe	Sch 10/Sch 40 Service Pipe
CSBSTU0100	2914 N	2914 N
CSBSTU0125	2914 N	2914 N
CSBSTU0150	2914 N	2914 N
CSBSTU0200	2914 N	-

图

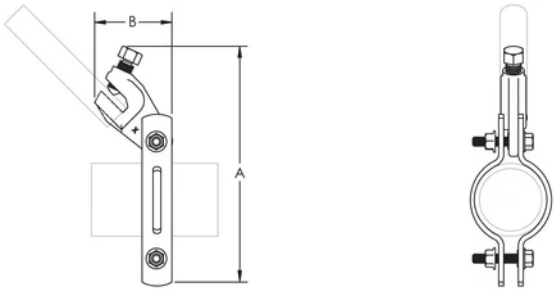

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

