

Strut Seismic Hinge Bracket Assembly



认证



功能

Used for installations where strut brace is parallel to structure

One wrench size fits all required hardware, eliminating the need to change tools

Shear-off head helps ensure correct torque and simplifies inspection

技术参数

完成: 电镀锌


材料: 钢

Table 1/1

物料号	订货号	孔尺寸 (HS)	宽度 (W)	厚度 (T)	A	B
CSBUS2PA	404603	20.6 mm	40.6 mm	6.4 mm	177.8 mm	47.8 mm
CSBUS1PA	404602	14.3 mm	40.6 mm	6.4 mm	177.8 mm	47.8 mm

FM Loads					
Part Number	Brace Member	Horizontal Capacity per Installation Angle from Vertical			
		30° - 44°	45° - 59°	60° - 74°	75° - 90°
CSBUS1PA	41 x 41 Strut Channel	5160 N	8290 N	8290 N	7470 N
CSBUS2PA	41 x 41 Strut Channel	5160 N	8290 N	8290 N	7470 N

图

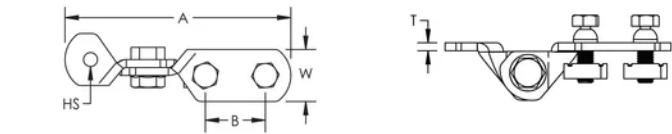

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美 +1.800.753.9221 ， 按 1 转客户服务 ， 按 2 转技术支持	欧洲 荷兰： +31 800-0200135 法国： +33 800 901 793	欧洲 德国： 800 1890272 其他国家/地区： +31 13 5835404	亚太地区 上海： + 86 21 2412 1618/19 悉尼： +61 2 9751 8500
--	---	---	--



我们强大的品牌组合：
CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

