

Branch Line Restraint Structure Attachment to Wood/Concrete

Data Solutions



认证



功能

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to wood or concrete where cracked concrete approval is not needed

技术参数

完成: 电镀锌

材料: 钢

Table 1/2

物料号	订货号	杆尺寸 (RS)	高度 (H)	长度 (L)	宽度 (W)	螺钉长度 (L)
-----	-----	----------	--------	--------	--------	----------


CSBBRS2MEG	402240	10, 12	28.2mm	40.4mm	26.9mm	44.5mm
CSBBRS2EG		0.375, 0.5	28.2mm	40.4mm	26.9mm	44.5mm

Table 2/2		
物料号	订货号	钻头直径
CSBBRS2MEG	402240	5mm
CSBBRS2EG		5mm

其他产品请

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

图

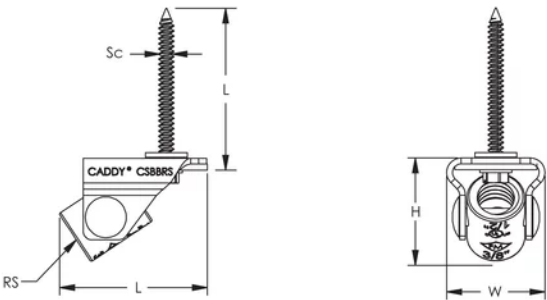

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE