


MI PDU, 1U, 60A(48A)NA/48A Int, 380-415V, 3P Wye, 9 CB, (9)4-in-1

Data Solutions

物料号

EN1966

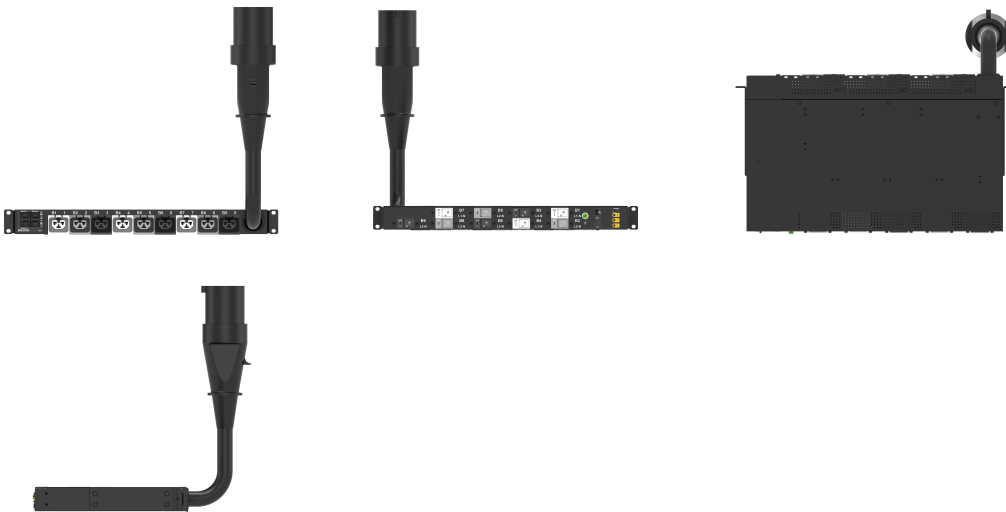

The Advantage Series Input Metered PDU family offers energy metering with advanced power and environmental monitoring options. Comprehensive monitoring at both the input phase and circuit breaker levels offers advanced alerts of potential overloads. Billing-grade metering provides accurate power consumption data for energy use optimization. The hot-swappable network management controller features Gigabit and redundant ethernet communication with advanced support for external environmental sensors and rack security access solutions.

产品属性

产品系列: Enlogic

产品类型: 插排

插座类型: (9) C13/C15/C19/C21

颜色: 黑色

开关插座: 否

断路器: 20 安

长度: 44mm

额定功率: 34.6 kVA 北美; 33.1 kVA 国际

断路器数量: 9

输入电压: 380 – 415V

相: 3 PH

孔数: 1

输出电压: 208 – 230VAC

标称电压: 415V

插头类型: IEC 60309 560P6 (IP44)

可拆卸输入电缆: 否

电流（降额电流）: 60 A (48 A) 北美; 48 A 国际

完成: 粉末涂层

机架单元: 1U

材料: 钢

类型: 智能 PDU

高度: 44mm

宽度: 444mm

深度: 269mm

重量: 7kg

包装数量: 1

输入电缆长度: 1.8m

其他产品详情

43 mm L x 444 mm W x 269 mm D, (269 mm D at CB)

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE