


MSPO PDU, 2U, 60A(48A)NA/63A Int, 208V NA, 230V Int, 1P, 4 CB, 12 Locking Combo

Data Solutions

物料号

EN6383

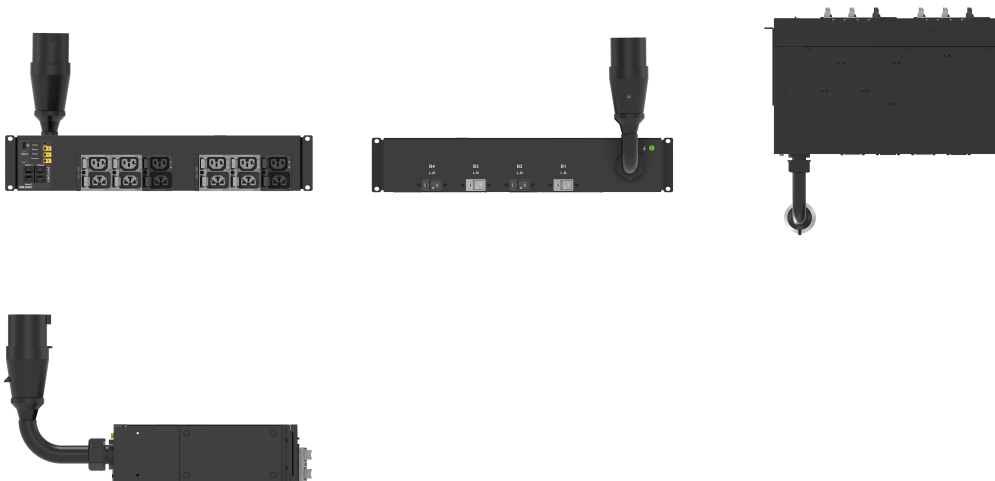

The Advantage Series Outlet Metered, Outlet Switched PDU family offers energy metering with advanced power and environmental monitoring options and remote outlet on/off switching. Comprehensive monitoring at the input phase, circuit breaker, and individual outlet levels offers advanced alerts of potential overloads. Billing-grade metering provides accurate power consumption data for energy use optimization. The hot-swappable network management controller features Gigabit and redundant ethernet communication with advanced support for external environmental sensors and rack security access solutions.

产品属性

产品系列: Enlogic

产品类型: 插排

插座类型: (6) 锁定 C13/C15; (6) 锁定 C13/C15/C19/C21

断路器: 20 安

颜色: 黑色

断路器数量: 4

开关插座: 是

长度: 87mm

额定功率: 11.5 kVA 北美; 14.5 kVA 国际

中断额定值: 5kAIC

孔数: 1

输入电压: 208V

相: 1 相

输出电压: 208 – 230VAC

插头类型: IEC 60309 360P6 (IP44)

标称电压: 230V

可拆卸输入电缆: 否

电流（降额电流）: 60 A (48 A) 北美; 63 A 国际

机架单元: 2U

类型: 智能 PDU

完成: 粉末涂层

计量类型: 插座

材料: 钢

高度: 87mm

重量: 8kg

宽度: 444mm

深度: 269mm

包装数量: 1

输入电缆长度: 3m

其他产品详情

87 mm L x 444 mm W x 269 mm D, (269 mm D at CB)

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE