 


# Disconnecting Link with Enclosure for Tape



## 功能

Allows for quick and easy disconnection of the earthing system to facilitate testing of the earth in isolation

High conductivity, hard drawn, electrolytic tough pitch copper per EN 13601

Includes stainless steel 304 enclosure, rubber dustproof, halogen-free polyamide insulators, stainless steel hardware

Rubber gland for tape connection

8 microns tinned finish according to ASTM B545 Service Class “C” for corrosive environments

## 技术参数

Table 1/3

| 物料号         | 材料                                   | 完成 | A      | B     | C     | 高度 (H)  |
|-------------|--------------------------------------|----|--------|-------|-------|---------|
| DLTBX253404 | Stainless Steel 304 (EN 1.4301), 镀锡铜 |    | 100 mm | 42 mm | 16 mm | 61.5 mm |
| DLCBX253404 | 不锈钢 304 (EN 1.4301), Copper          | 裸露 | 100 mm | 42 mm | 16 mm | 61.5 mm |

Table 2/3

| 物料号         | 厚度 (T) | 螺纹尺寸 (TS) | 长度 1 (L1) | 长度 2 (L2) | 长度 3 (L3) | 长度 4 (L4) |
|-------------|--------|-----------|-----------|-----------|-----------|-----------|
| DLTBX253404 | 4 mm   | M8        | 125 mm    | 170 mm    | 150mm     | 110 mm    |


| 物料号         | 厚度 (T) | 螺纹尺寸 (TS) | 长度 1 (L1) | 长度 2 (L2) | 长度 3 (L3) | 长度 4 (L4) |
|-------------|--------|-----------|-----------|-----------|-----------|-----------|
| DLCBX253404 | 4 mm   | M8        | 125 mm    | 170 mm    | 150mm     | 110 mm    |

| Table 3/3   |           |           |           |         |
|-------------|-----------|-----------|-----------|---------|
| 物料号         | 宽度 1 (W1) | 宽度 2 (W2) | 宽度 3 (W3) | 单位重量    |
| DLTBX253404 | 40 mm     | 150 mm    | 170mm     | 1.19 kg |
| DLCBX253404 | 40 mm     | 150 mm    | 170mm     | 1.19 kg |

### 其他产品详情

Available tape size 25 x 3 mm to 40 x 4 mm.

### 图

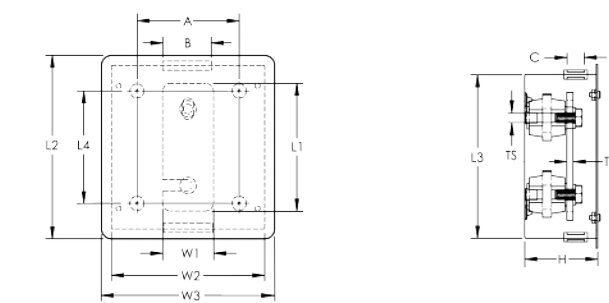

### 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221  
，按 1 转客户服务  
，按 2 转技术支持

欧洲

荷兰：  
+31 800-0200135  
法国：  
+33 800 901 793

欧洲

德国：  
800 1890272  
其他国家/地区：  
+31 13 5835404

亚太地区

上海：  
+ 86 21 2412 1618/19  
悉尼：  
+61 2 9751 8500



我们强大的品牌组合：

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE