

围栏夹钳，两个导体



The nVent ERICO Fence Clamp, Two Conductors, is designed for grounding and bonding applications on fences, pipes, or pedestals where two separate conductors must be securely connected. This clamp ensures a reliable, high-quality electrical connection for system safety and integrity in various utility and industrial settings. Constructed from corrosion-resistant materials and engineered for durability, it is dependable for establishing effective grounding paths using two conductors.

认证



功能

防盗外观

已包含不锈钢硬件

镀锡能够尽可能降低腐蚀风险

Made from high quality copper alloy that minimizes the risk of corrosion while ensuring reliable conductivity

技术参数


完成： 镀锡

Table 1/1

物料号	材料	围柱标称尺寸	围柱实际外径 (Ø)	导体尺寸
FC076DH	Copper Alloy, 不锈钢 304 (EN 1.4301)	2"	60.45 mm	#4 实心线 - 250 千圆密耳绞合线, 16 mm² Stranded - 120 mm² Stranded

物料号	材料	围柱标称尺寸	围柱实际外径 (Ø)	导体尺寸
FC078DH	Copper Alloy, 不锈钢 304 (EN 1.4301)	2 1/2"	73.15 mm	#4 实心线 - 250 千圆密耳绞合线, 16 mm ² Stranded - 120 mm ² Stranded
FC082DH	Copper Alloy, 不锈钢 304 (EN 1.4301)	3 1/2"	101.6 mm	#4 实心线 - 250 千圆密耳绞合线, 16 mm ² Stranded - 120 mm ² Stranded

图

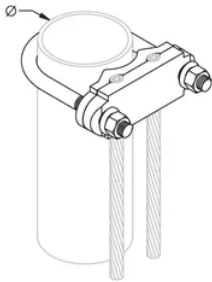

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE