


# Partial SF Transversal Support Bar, SFBP, 106x562x31mm, Zinc Plated, Mild Steel

## 物料号

### SFBP600

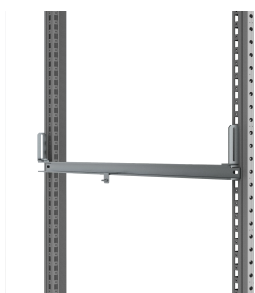

这些支撑杆使半高摇架可安装在壁挂式和落地式钢制机柜中，是一种牢靠的固定方法。

## 功能

Description: Enables partial height swing frames to be mounted in wall mounted, steel enclosures, and floor standing, combinable, steel enclosures. The swing frames can be mounted to allow both left and right hand opening.

Material: 3 mm zinc plated steel.

Pack quantity: 1 complete kit including mounting brackets for one swing frame.

Mounting requirements: For wall mounted, steel enclosures, use in combination with the AVB profiles. For floor standing enclosures, it can be mounted directly to the enclosure frame or adjustable in depth, in steps of 25 mm, by means of the CLPK.

## 产品属性

订货号: SFBP600

高度: 106mm

宽度: 600mm

深度: 31mm

材料: 低碳钢

完成: 镀锌

厚度: 3mm

重量: 2.3kg

包装数量: 1

外壳材料: 低碳钢

## 警告

---

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**