

End Alignment Fitting



End alignment fittings properly locate the sleeve onto the reinforcing steel. The fittings also retain the packing materials and hold them in place, which helps ensure a leak-free installation.

功能

Durable, re-usable and long lasting

Easily replaced if damaged

Split-collar design allows for easy installation and removal

技术参数

材料: 钢

Table 1/2

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	高度 (H)	直径 1 (Ø1)	直径 2 (Ø2)
RBM2974125X	20 mm	#6	20M	64 mm	70 mm	39 mm
RBM2767100E	28 mm	#9	30M	64 mm	70 mm	58 mm
RBM267156K	57 mm	#18	55M	64 mm	111 mm	87 mm
RBM266975G	43 mm	#14	45M	64 mm	86 mm	76 mm
RBM2870100A	22 mm	#7		64 mm	70 mm	42 mm

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	高度 (H)	直径 1 (Ø1)	直径 2 (Ø2)
RBM2671100M	57 mm	#18	55M	64 mm	111 mm	96 mm
RBM2687126G	36 mm	#11	35M	64 mm	86 mm	71 mm
RBM2669125J	43 mm	#14	45M	64 mm	86 mm	77 mm
RBM2886112C	25 mm	#8	25M	64 mm	70 mm	49 mm
RBM2759K	36 mm	#11	35M	64 mm	102 mm	87 mm
RBM2748100D	28 mm	#9	30M	64 mm	70 mm	55 mm
RBM2886150D	25 mm	#8	25M	64 mm	70 mm	55 mm
RBM2669100H	43 mm	#14	45M	64 mm	86 mm	74 mm
RBM2671125N	57 mm	#18	55M	64 mm	111 mm	99 mm
RBM275075E	32 mm	#10		64 mm	70 mm	58 mm
RBM2750125F	32 mm	#10		64 mm	76 mm	65 mm
RBM267150K	57 mm	#18	55M	64 mm	111 mm	87 mm
RBM2974100U	20 mm	#6	20M	64 mm	70 mm	36 mm
RBM266785F	36 mm	#11	35M	64 mm	76 mm	65 mm
RBM267885K	43 mm	#14	45M	64 mm	102 mm	87 mm

Table 2/2

物料号	包装数量
-----	------

RBM2974125X	1
RBM2767100E	1
RBM267156K	1
RBM266975G	1
RBM2870100A	1
RBM2671100M	1
RBM2687126G	1
RBM2669125J	1
RBM2886112C	1
RBM2759K	1
RBM2748100D	1
RBM2886150D	1
RBM2669100H	1
RBM2671125N	1
RBM275075E	1
RBM2750125F	1
RBM267150K	1

RBM2974100U	1
RBM266785F	1
RBM267885K	1


其他产品详情

Diameter 2 is the mating surface for the outside diameter of the appropriate sleeve.

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

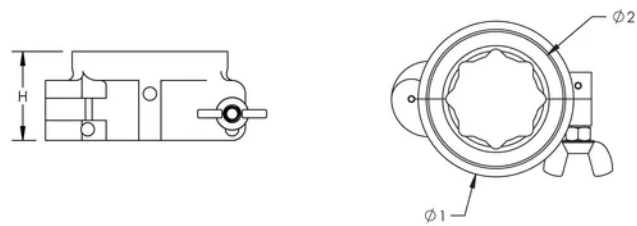

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE