


Horizontal Pouring Basin, Top Fill, 90°

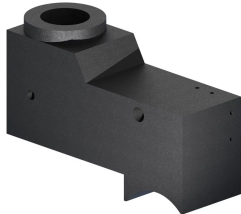

90 degree top fill horizontal pouring basins are used when structural interferences are directly above the tap hole in the sleeve.

功能

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal top fill sleeves

技术参数

材料: 石墨

Table 1/1

物料号	直径 (Ø)	长度 1 (L1)	长度 2 (L2)	宽度 (W)	高度 [1] (H1)	高度 [2] (H2)
RB TSA9040X	38 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSA9735X	38 mm	248 mm	76 mm	76 mm	140mm	89mm
RB TSA6040F	64 mm	152 mm	76 mm	76 mm	140mm	102mm
RB TSA9740A	41 mm	248 mm	76 mm	76 mm	140mm	102mm
RB TSA7040J	76 mm	179 mm	76 mm	76 mm	140mm	102mm

物料号	直径 (Ø)	长度 1 (L1)	长度 2 (L2)	宽度 (W)	高度 [1] (H1)	高度 [2] (H2)
RB TSA9040C	48 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSA9740C	48 mm	248 mm	76 mm	76 mm	140mm	102mm
RB TSA9040D	54 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSB15045D	54 mm	381 mm	76 mm	76 mm	152mm	114mm
RB TSB12040E	57 mm	305 mm	76 mm	76 mm	152mm	102mm
RB TSA9040F	64 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSB12042F	64 mm	305 mm	76 mm	76 mm	152mm	108mm
RB TSA9040J	76 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSB13545J	76 mm	342 mm	76 mm	76 mm	152mm	114mm
RB TSA9040M	95 mm	229 mm	76 mm	76 mm	140mm	102mm
RB TSB12050M	95 mm	305 mm	76 mm	76 mm	152mm	127mm
RB TSB15045M	95 mm	381 mm	76 mm	76 mm	152mm	114mm
RB TSB18550M	95 mm	470 mm	76 mm	76 mm	152mm	127mm
RB TSC18550M	95 mm	470 mm	76 mm	76 mm	179mm	127mm
RB TSC26050M	95 mm	660 mm	76 mm	76 mm	179mm	127mm


其他产品详情

RB TSA pouring basins require one RBW341 pouring basin frame. RB TSB and RB TSC pouring basins require one RBW341 pouring basin frame and two RBS5000 bolt retainers (all sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

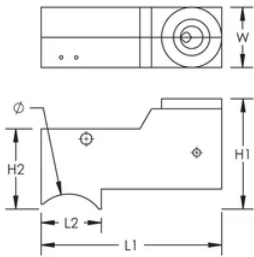

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE