

Horizontal Pouring Basin, Top Fill, Extended



Extended top fill horizontal pouring basins are used when structural interferences are directly above the tap hole in the sleeve.

功能

Made from heat-resistant graphite

Durable, re-usable and long lasting

Designed for use with T-Series and B-Series horizontal top fill sleeves

技术参数

材料: 石墨

Table 1/1

物料号	直径 (Ø)	长度 1 (L1)	长度 2 (L2)	宽度 (W)	高度 [1] (H1)	高度 [2] (H2)
RBHA9735U	35 mm	248 mm	70 mm	76 mm	140mm	92mm
RBHA6037F	64 mm	152 mm	70 mm	76 mm	140mm	99mm
RBHA9735X	38 mm	248 mm	70 mm	76 mm	140mm	92mm
RBHA9740A	41 mm	248 mm	70 mm	76 mm	140mm	102mm

物料号	直径 (Ø)	长度 1 (L1)	长度 2 (L2)	宽度 (W)	高度 [1] (H1)	高度 [2] (H2)
RBHA7037J	76 mm	178 mm	70 mm	76 mm	140mm	99mm
RBHA9740C	48 mm	248 mm	70 mm	76 mm	140mm	102mm
RBHA9037M	95 mm	229 mm	70 mm	76 mm	140mm	99mm
RBHA6050E	57 mm	152 mm	70 mm	76 mm	140mm	127mm
RBHA6050F	64 mm	152 mm	70 mm	76 mm	140mm	127mm


其他产品详情

RBHA pouring basins require one RBM2890S pouring basin frame (sold separately).

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

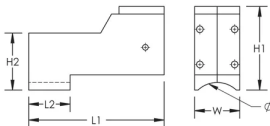

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE