


# nVent LENTON Form Saver with Large Anchor, D6SA

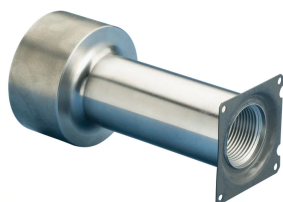

The nVent LENTON Form Saver with Large Anchor provides a method of splicing reinforcing bar in segmental concrete construction applications that have limited space or are severely congested. The large head significantly reduces required embedment length of the mating reinforcing bar.

Typically used in beam/column applications, the nVent LENTON Form Saver with Large Anchor easily attaches to the form panels. When the form is stripped, the protected threaded end of the coupler is exposed. Simply remove the protective cap and install the nVent LENTON taper threaded dowel bar. This system eliminates hooked bar congestion, protruding dowels and the need to drill holes in expensive formwork.

## 功能

Durable mounting plates allow for easy attachment to forms

Built-in thread cover or screw-in plug protects internal threads from concrete paste contamination

Head area exceeds 5x bar area (net 4x)

Coupler and anchor head are one piece

Available in customer specified lengths

## 技术参数

完成: 普通  
材料: 钢  
100% 美国国内内容: 是

Table 1/2

 
| 物料号 | 钢筋尺寸, 公制 | 钢筋尺寸, 美国 | 钢筋尺寸, 加拿大 | 直径 1 (Ø1) | 直径 2 (Ø2) | 高度 (H) |
|-----|----------|----------|-----------|-----------|-----------|--------|
|-----|----------|----------|-----------|-----------|-----------|--------|

|              |       |     |     |       |       |       |
|--------------|-------|-----|-----|-------|-------|-------|
| EL25D6SA0600 | 25 mm | #8  | 25M | 35 mm | 57 mm | 57 mm |
| EL25D6SA0725 | 25 mm | #8  | 25M | 35 mm | 57 mm | 57 mm |
| EL25D6SA0800 | 25 mm | #8  | 25M | 35 mm | 57 mm | 57 mm |
| EL25D6SA0900 | 25 mm | #8  | 25M | 35 mm | 57 mm | 57 mm |
| EL25D6SA1800 | 25 mm | #8  | 25M | 35 mm | 57 mm | 57 mm |
| EL32D6SA0600 | 32 mm | #10 | 32M | 48 mm | 76 mm | 64 mm |

| Table 2/2    |        |         |         |
|--------------|--------|---------|---------|
| 物料号          | 长度 (L) | 杆深 (BD) | 单位重量    |
| EL25D6SA0600 | 152mm  | 34mm    | 1.56 kg |
| EL25D6SA0725 | 184mm  | 34mm    | 1.79 kg |
| EL25D6SA0800 | 203mm  | 34mm    | 1.94 kg |
| EL25D6SA0900 | 229mm  | 34mm    | 2.13 kg |
| EL25D6SA1800 | 457mm  | 34mm    | 3.84 kg |
| EL32D6SA0600 | 152mm  | 40mm    | 2.7 kg  |

## 其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.



警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

| 北美              | 欧洲              | 欧洲             | 亚太地区                 |
|-----------------|-----------------|----------------|----------------------|
| +1.800.753.9221 | 荷兰：             | 德国：            | 上海：                  |
| ，按 1 转客户服务      | +31 800-0200135 | 800 1890272    | + 86 21 2412 1618/19 |
| ，按 2 转技术支持      | 法国：             | 其他国家/地区：       | 悉尼：                  |
|                 | +33 800 901 793 | +31 13 5835404 | +61 2 9751 8500      |



我们强大的品牌组合：

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE