

nVent LENTON Interlok Position Transition Grout-Fill Coupler



功能

Designed to splice different diameter bars

Positional feature allows the threaded coupler end to telescope out to close a gap between forms and to allow alignment of the grout tubes

Over-sized cavity allows for greater field tolerance

Taper-threaded end helps prevent movement of the reinforcing bars and eliminate misalignment

Requires less grout than most competitive systems

技术参数

材料: 铸铁

完成: 普通

包装: 标准

Table 1/2

物料号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 1 (Ø1)	直径 2 (Ø2)	长度 1 (L1)
LK1110STHD	36 mm, 32 mm	#11, #10		80 mm	62 mm	384 mm

物料号	钢筋尺寸，公制	钢筋尺寸，美国	钢筋尺寸，加拿大	直径 1 (Ø1)	直径 2 (Ø2)	长度 1 (L1)
LK1411STHD	43 mm, 36 mm	#14, #11	45M, 35M	94 mm	70 mm	456 mm


Table 2/2					
物料号	长度 2 (L2)	长度 3 (L3)	杆深 (BD)	联轴器主体 (CB)	单位重量
LK1110STHD	410 mm	251mm	40mm	305mm	4.59 kg
LK1411STHD	481 mm	324mm	43mm	386mm	8.62 kg

其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

Prior to installation, please read and understand the detailed instructions and safety notices provided in the nVent LENTON Interlok Instruction Manual.

图

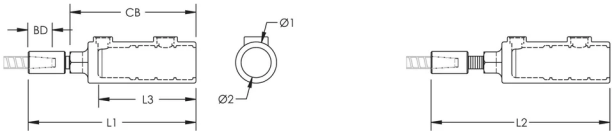

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE