

nVent LENTON Speed Sleeve Coupler



The nVent LENTON Speed Sleeve splice is a proven, quick and economical method of making compression-only splices in steel reinforced concrete projects. The system is designed to allow compressive loads to be transferred by aligning square cut reinforcing steel bar ends.

nVent LENTON Speed Sleeve is simple and easy to install. The small dimensions of the sleeve generally eliminate the need for additional concrete cover on the reinforcing steel because the sleeve is typically thinner than the column stirrups.

功能

Bars can be individually secured

Fast, one-man installation

Requires only a lightweight ratchet wrench to install

Can be used on bundled bars

Self supporting; no tack welding is needed

Transition splices can be made using simple adaptor inserts

技术参数

完成: 电镀锌

材料: 钢

Table 1/2

物料号	订货号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	长度 (L)	宽度 (W)
RBW26810	145535	32 mm	#10		154mm	67 mm
RBW2687	145500	22 mm	#7		152mm	64 mm

物料号	订货号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	长度 (L)	宽度 (W)
RBW2686	145495	20 mm	#6	20M	154mm	54 mm
RBW2688	145510	25 mm	#8	25M	154mm	55 mm
RBW2689	145520	28 mm	#9	30M	154mm	63 mm
RBW26811	145540	36 mm	#11	35M	203mm	67 mm
RBW26814		43 mm	#14	45M	280mm	77 mm
RBW26818	145560	57 mm	#18	55M	305mm	92 mm
RBW26840MM	145550	40 mm			280mm	74 mm
RBW26850	145555	50 mm			300mm	89 mm

Table 2/2					
物料号	订货号	高度 (H)	插座宽度 (SW)	螺栓数量	单位重量
RBW26810	145535	47 mm	16mm	4	0.28 kg
RBW2687	145500	45 mm	16mm	3	0.53 kg
RBW2686	145495	37 mm	16mm	3	0.54 kg
RBW2688	145510	42 mm	16mm	3	0.59 kg
RBW2689	145520	45 mm	16mm	3	0.59 kg
RBW26811	145540	54 mm	16mm	4	0.91 kg
RBW26814		52 mm	16mm	4	1.38 kg

物料号	订货号	高度 (H)	插座宽度 (SW)	螺栓数量	单位重量
RBW26818	145560	69 mm	16mm	4	2.29 kg
RBW26840MM	145550	52 mm	16mm	4	1.35 kg
RBW26850	145555	64 mm	16mm	4	1.6 kg


其他产品详情

nVent LENTON Speed Sleeve is a compression-only splicing system. It should never be used for tension applications.

Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the installation instructions.

图

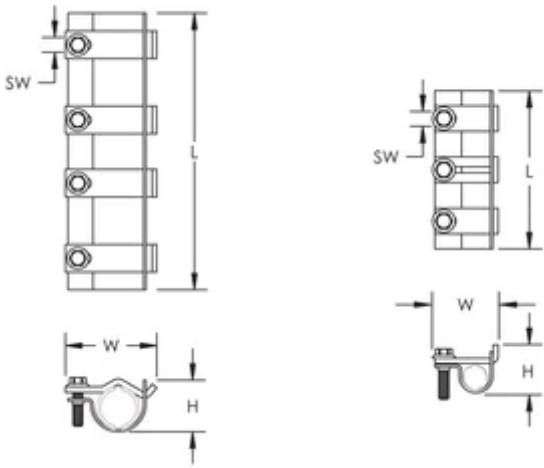

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE